

Branch Line Restraint Structure Attachment to Threaded Hole



VLASTNOSTI

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to concrete anchors or structural attachments with female threads

Can be used for bolting through steel



SPECIFIKACE

Table 1/2


Katalogové číslo	Article Number	Materiál	Povrchová úprava	Rod Size (RS)	Height (H)	Length (L)
CSBBRS3MEG	402241	Ocel	Electrogalvanized	10, 12	28.2 mm	40.4mm

Table 2/2

Katalogové číslo	Article Number	Width (W)	Screw Diameter (Sc)	Screw Length (L)
CSBBRS3MEG	402241	26.9 mm	10	19mm

DALŠÍ PODROBNOSTI O PRODUKTU

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

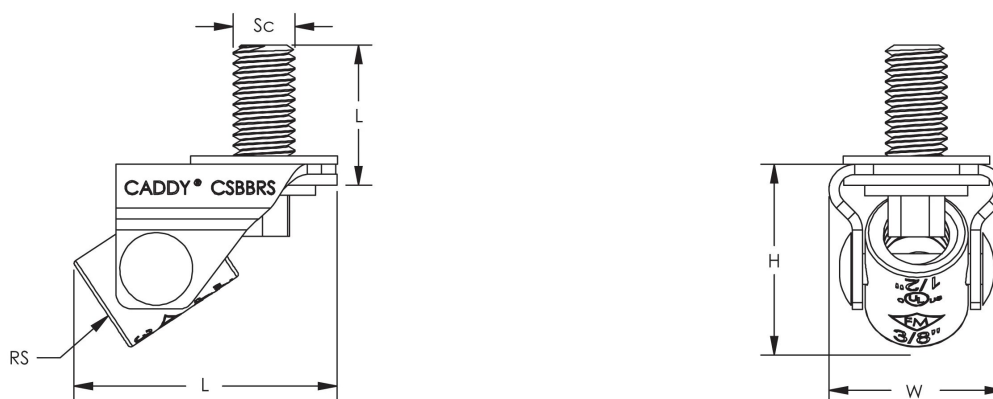

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

