

nVent CADDY Pyramid H-Frame Kit



VLASTNOSTI

Foam or rubber bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Rubber rooftop interface ideal for solar panel array installations

Kit includes 2 post bases with pre-installed mounting hardware, 6 bolts, 6 strut nuts, and 2 L-brackets to complete H-frame

Hot-dip galvanized and UV stabilized for long lasting performance

Accepts standard strut channels



SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Materiál	Temperature	Static Load Safety Factor	Rooftop Interface	Strut Type
PHK	360420	Polypropylene, Polyetylen	-34.4 to 54 °C	3:1	Foam	A (41 x 41 mm)


Table 2/2

Katalogové číslo	Article Number	Height (H)	Length (L)	Width (W)	Surface Area	Static Load
PHK	360420	117 mm	314mm	314 mm	0.18m ²	6670N

DALŠÍ PODROBNOSTI O PRODUKTU

Static load represents 750 lb (3,335 N) per post base. The end user must select and evaluate the strut framing to ensure the assembled H-frame can properly support the applied load.

DIAGRAMS

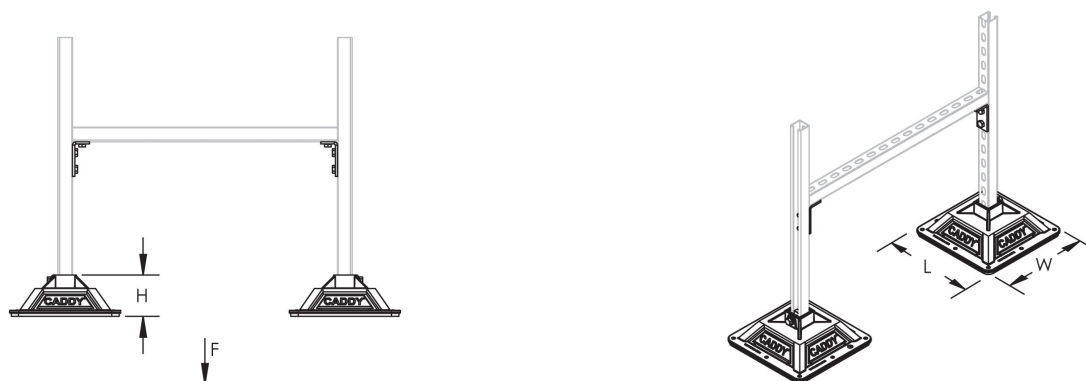

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

