

Uniklip Flat Elbow



VLASTNOSTI

Creates a 90° horizontal change in cable tray direction

Provides optimal support for high-performance low voltage and data cables

Innovative UNIKLIP installation system that installs up to three times faster

IEC 61537 load rating and earthing compliant

No field cutting or modifications required; just drop it in and keep installing the cable tray

Eliminates safety related concerns around field cutting

 

Tool-free, integrated couplers with Uniklip

Povrchová úprava: Pregalvanized
Materiál: Ocel



SPECIFIKACE

Katalogové číslo	Article Number	Width (W)	Hloubka (D)	Length (L)	Angle (a)	A	B
PCT50X300FB90	850150	300 mm	49mm	905mm	90 °	415 mm	91 mm
PCT50X075FB90	850110	75 mm	49mm	587mm	90 °	192 mm	91 mm
PCT50X600FB90	850180	600 mm	49mm	1329mm	90 °	715 mm	91 mm
PCT50X100FB90	850120	100 mm	49mm	622mm	90 °	216 mm	91 mm
PCT50X500FB90	850170	500 mm	49mm	972mm	90 °	590 mm	91 mm
PCT50X150FB90	850130	150 mm	49mm	693mm	90 °	265 mm	91 mm
PCT50X450FB90	850160	450 mm	49mm	1117mm	90 °	565 mm	91 mm
PCT50X225FB90	850140	225 mm	49mm	799mm	90 °	340 mm	91 mm
PCT50X050FB90	850100	50 mm	49mm	550mm	90 °	167 mm	91 mm

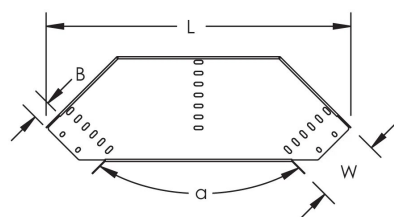

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

