

nVent ERICO Hammerlock Ground Clamp



The nVent ERICO Hammerlock irreversible mechanical connection connects the grounding conductor to the ground rod. Machined from highly conductive copper, the state-of-the-art Hammerlock provides a low resistance connection designed to withstand ground fault currents and lightning transients. The connector's mechanically rugged design will help ensure that the highest level of performance is maintained for many years after the connection has been buried in the harsh underground environment.

Installing the Hammerlock is as easy as swinging a hammer and requires no special tools or training. The Hammerlock can be installed three to five times faster than an acorn clamp and provides a high-quality grounding connection that is easy to use and withstands 100% of the current carrying capacity of the conductor.

VLASTNOSTI

Irreversible connection with excellent mechanical strength

Fast and simple installation requires only a hammer

No special training required

Low resistance connection

Provides a visual indication of completed connection

Allows for "T" or pass-through connections

Suitable for Copperweld® steel conductors

Material: Copper
Ground Rod Type: Copper-bonded




SPECIFIKACE

Katalogové číslo	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size	Number of Conductors	Certifications
EHL12FC1K	1/2"	12.7 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	1	UL, cUL
EHL12FC2G	1/2"	12.7 mm	1/0 Stranded - 2/0 Stranded	1	UL, cUL

Katalogové číslo	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size	Number of Conductors	Certifications
EHL12FC1V	1/2"	12.7 mm	#4 Stranded - #2 Stranded, 25 mm ² Stranded	1	cUL, UL
EHL12FC1K1K	1/2"	12.7 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	2	
EHL58C2G	5/8"	14.2 mm	1/0 Stranded - 2/0 Stranded	1	cUL, UL
EHL58C1V	5/8"	14.2 mm	#4 Stranded - #2 Stranded, 25 mm ² Stranded	1	cUL, UL
EHL58C1K	5/8"	14.2 mm	#6 Solid - #4 Solid, 16 mm ² Stranded, #2 Solid	1	cUL, RUS, UL
EHL58C1K1K	5/8"	14.2 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	2	UL, cUL
EHL34C2G	3/4"	17.3 mm	1/0 Stranded - 2/0 Stranded, #2 Solid	1	cUL, UL
EHL34C1K	3/4"	17.3 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	1	cUL, UL
EHL34C1V	3/4"	17.3 mm	#4 Stranded - #2 Stranded, 25 mm ² Stranded	1	UL, cUL

DIAGRAMS

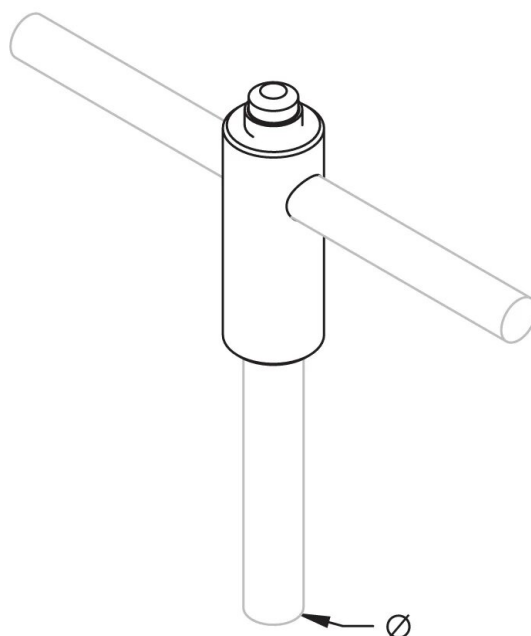

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE