

Rail Four Post Terminal Block

VLASTNOSTI

Separates "clean" wiring from "dirty" wiring

Includes integrated test terminal

Includes slot for low-impedance busbar

Modular design for field assembly and future expansion

Meets AAR recommendations



SPECIFIKACE



Katalogové číslo	Length (L)	Hloubka (D)	Height (H)	A	B	Thread Size (TS)	Hardware Included
B2700A2C1WH	133.35mm	25.4mm	31.75 mm	25.4 mm	60.3 mm	14" UNS	Yes
SBB2700A2B10	133.35mm	25.4mm	31.75 mm	25.4 mm	60.3 mm	14" UNS	No

DALŠÍ PODROBNOSTI O PRODUKTU

B2700A2C1WH kit includes: (1) terminal block, (1) offset test link, (15) 9/16" outer diameter copper flat washers, (9) zinc plated binding 14-24 UNS-2B hex nuts AAR, (5) nickel plated jam 14-24 UNS-2B hex nuts AAR, (2) #10X1 – 1/2" zinc plated screws, and (1) instruction print.

Four Post Terminal Blocks are components included in nVent ERICO pre-engineered and manufactured panels.

Design assistance is available for special applications. Contact your nVent ERICO representative for more details.

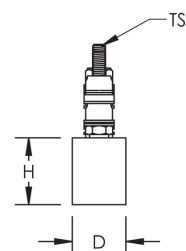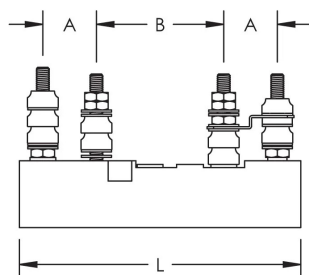

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE