

Threaded Coupler for Copper-Bonded Ground Rod, Threaded

VLASTNOSTI

High-strength couplings are threaded and chamfered at both ends for easy driving

Corrosion-resistant couplings ensure permanent, low resistance copper-to-copper connections



SPECIFIKACE

Table 1/2


Katalogové číslo	Article Number	Materiál	Ground Rod Diameter, Nominal	Length (L)	Thread Size (TS)	Unit Weight
CR58	158040	Bronze	5/8"	61mm	5/8" UNC	0.09 kg
CR34		Bronze	3/4"	76.2mm	3/4" UNC	0.15 kg
SC34	158050	Bronze	3/4"	71mm	3/4" UNC	0.17 kg
CR100		Silicon Bronze	1"	99.1mm	1" UNC	0.35 kg

Table 2/2

Katalogové číslo	Article Number	Complies With	Certifications
CR58	158040	EN IEC 62561-2	UL, cUL, RUS, CSA-US, CSA
CR34			RUS, CSA-US, UL, cUL, CSA
SC34	158050	IEC® EN 62561-2	

Katalogové číslo	Article Number	Complies With	Certifications
CR100		EN IEC 62561-2	cUL, UL

DIAGRAMS

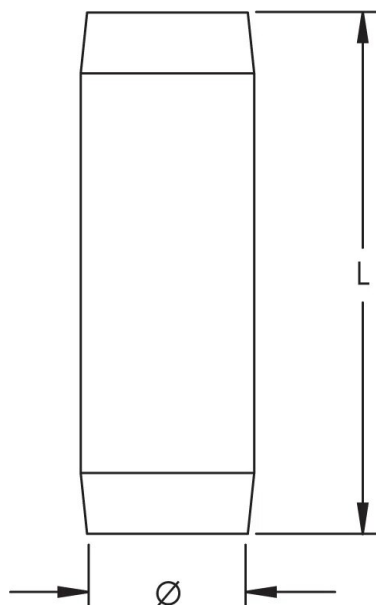

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE