


Countersunk Screw

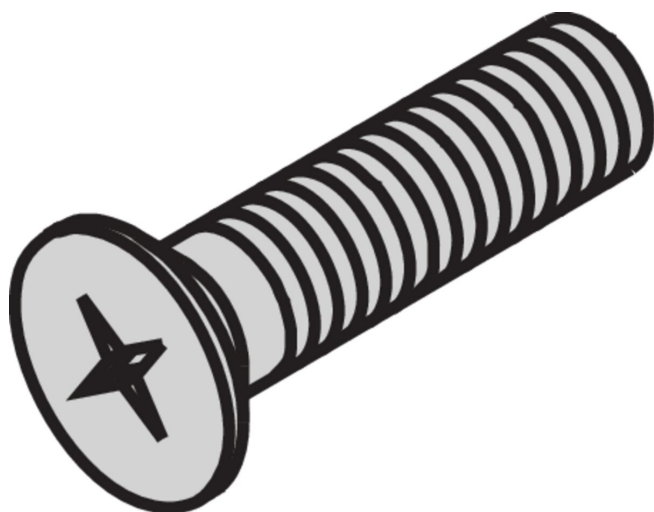

Flush surface, no interference with sliding parts. Self-centering in precision countersink. Clean external geometry (important for hygiene or airflow).

VLASTNOSTI

Countersunk screws are used for numerous mounting options in a subrack or desktop case.

Cross Recess imprint offers a high level of torque to achieve quick and easy installation

Torx imprint bears greater torque

The Torx star-shaped head prevents cam-out

Product Type: Screw



SPECIFIKACE

Table 1/2

Katalogové číslo	Length	Materiál	Povrchová úprava	Množství v balení	Thread Size	Výška
24560-139	5mm	Ocel	Pozinkovaná Ocel	100	M4	
24560-183	12mm	Ocel	Pozinkovaná Ocel	100	M5	
24560-182	12mm	Ocel	Pozinkovaná Ocel	4	M5	
24560-145	14mm	Ocel	Pozinkovaná Ocel	100	M4	
24560-164	8mm	Ocel	Nickel Plated	100	M2.5	4.7mm
24560-158	7.7mm	Ocel	Pozinkovaná Ocel	100	M2.5	
21100-542	8mm	Ocel	Nickel Plated	100	M3	
21100-429	8mm	Ocel	Nickel Plated	100	M2.5	
21100-649	10mm	Ocel	Pozinkovaná Ocel	100	M2.5	
21100-500	10mm	Ocel	Nickel Plated	100	M2.5	
21100-507	12mm	Ocel	Nickel Plated	100	M2.5	

Table 2/2

Katalogové číslo	Typ	Šířka	Works With	Thread Type	Torque
24560-139	Countersunk Screw		Front Panels		1.3N·m

Katalogové číslo	Typ	Šířka	Works With	Thread Type	Torque
24560-183	Countersunk Screw		Front Panels		2.4N·m
24560-182	Countersunk Screw		Front Panels		2.4N·m
24560-145	Countersunk Screw		Front Panels		2.4N·m
24560-164	Countersunk Screw	4.7mm	Front Panels	Metric	
24560-158	Countersunk Screw		Front Panels		
21100-542	Screw		Front Panels		
21100-429	Screw		Front Panels		
21100-649	Screw		Front Panels		
21100-500	Screw		Front Panels		
21100-507	Screw		Front Panels		

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE