

VXS System, Tower, 5 U, 7 Slot, Pluggable PSU

Phase-out

KATALOGOVÉ ČÍSLO

10836-060

VXS tower system for 7 VXS boards 6 U, 160 mm. With Rear I/O option The power for the system is supplied by a pluggable open frame power supply.

VLASTNOSTI




System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; Backplane, conforms to VITA 41.0, -41.1, -41.10, -41.11

PSU, 19" compatible, 300 W; a second PSU can optionally be fitted

Backplane VXS/VME64x4 slot VME64x, 6 U, with P0 plug3 x VXS payload slots connected as ring

Heat dissipation by 4 fans, cooling from front to rear side; temperature-controlled with fan control module (FCM)

Display module for DC operating voltages, fan and temperature alarm

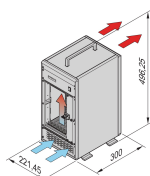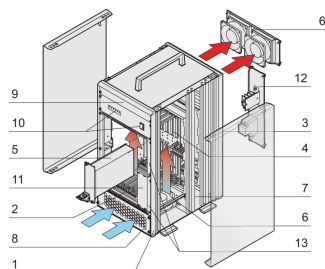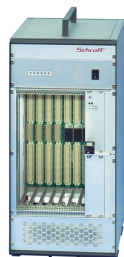

VLASTNOSTI PRODUKTU

Product Type: System

Hloubka: 300mm

Výška: 496.25mm

Šířka: 221.45mm

Power: 250W

Net Weight: 13.5kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DALŠÍ PODROBNOSTI O PRODUKTU

Modified systems available on request.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE