


PSU 19" for CompactPCI, DC/DC, 3 U, 8 HP

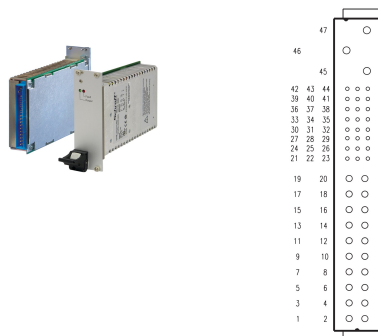

Obsolete

KATALOGOVÉ ČÍSLO

13100-142

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

VLASTNOSTI

Connector P47 and CompactPCI signalling

4 output voltages

Redundant operation with Current Share Bus (CSB), hot-swap



VLASTNOSTI PRODUKTU

Product Type: Power Supply

Typ: 19" DC/DC Converter

Works With: CompactPCI and VME64x

Vstupní napětí DC: 36 – 75V

Power: 250W

Number of Output Voltages: 4

Voltage 1: 5V

Current 1: 40A

Voltage 2: 3.3V

Current 2: 40A

Voltage 3: 12V

Current 3: 5.5A

Voltage 4: -12V

Current 4: 2A

Rack Height: 3U

Rack Width: 8HP

Hloubka: 171.93mm

Net Weight: 0.94kg

Množství v balení: 1

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY **ERICO** **HOFFMAN** **ILSCO** **SCHROFF** **TRACHTE**