


**Insertor/Extractor Handle Type IEL, Black Lever,
Grey Button, Bottom; 10 pieces**

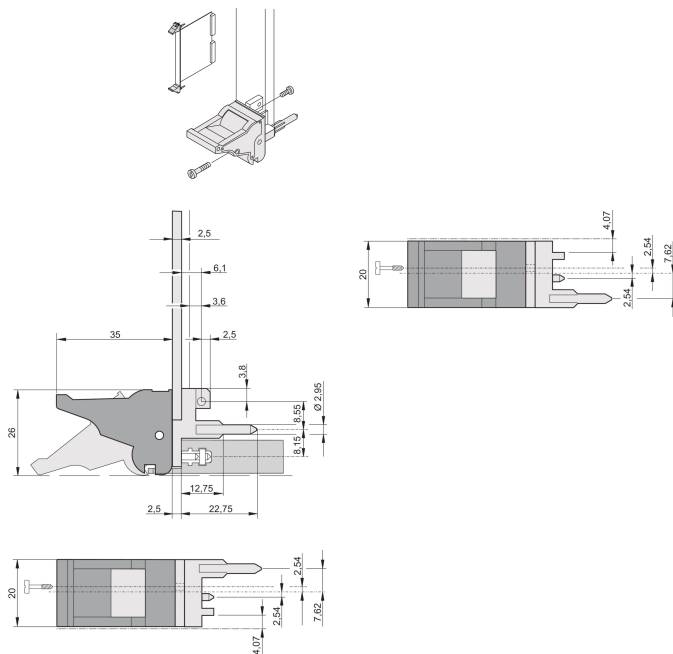

KATALOGOVÉ ČÍSLO

20817-612

The inserter/extractor handle, type IEL in accordance with IEEE 1101.10. Two of these handles can overcome a single lever force of 700N (per pair).

VLASTNOSTI

Suitable for insertion and extraction forces up to 700 N
(per pair)

In accordance with IEEE 1101.10 and IEC 60297-3-102

A microswitch can be mounted



VLASTNOSTI PRODUKTU

Množství v balení: 10

Typ rukojeti: IEL; Bottom Front; Top Rear I/O

Flammability Rating: UL® 94V-0

Barva: Jet Black

Kód barvy: RAL 9005

Complies With: EN 45545-2

Hloubka (D): 60.45mm

Výška (H): 25.5mm

Materiál: Polycarbonate; Zinc Alloy

Product Type: Handle

Typ: Inserter/Extractor, Standard

Šířka (W): 19.8mm

Works With: Front Panels


Gross Weight: 0.246kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DALŠÍ PODROBNOSTI O PRODUKTU

Please order Coding pegs and Microswitch separately.

DIAGRAMS

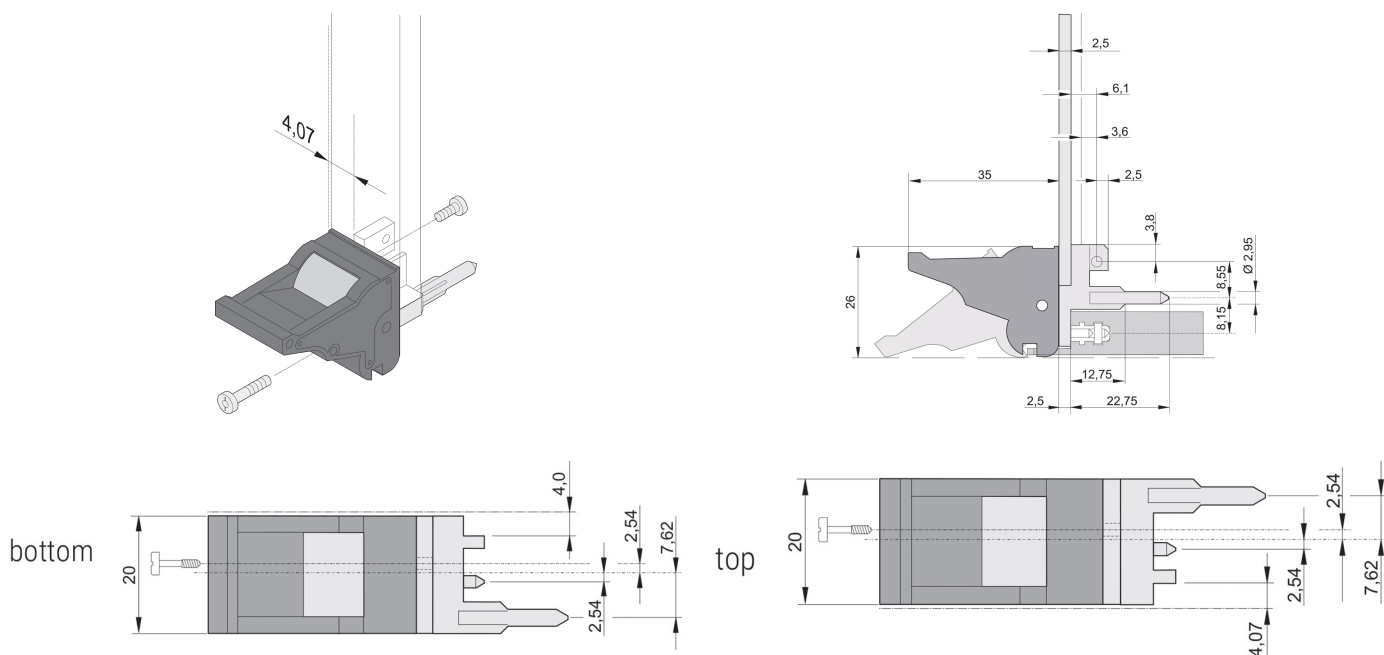

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE