


# EuropacPRO 19" Subrack Kit for Backplane, Heavy, Shielded

EMC Shielded subrack for backplane mounting, heavy version with tox welded side panels.

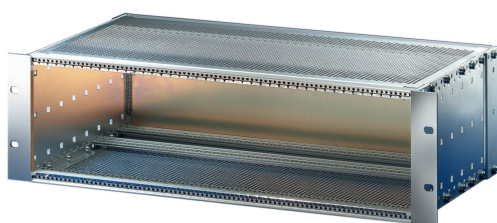

## VLASTNOSTI

Subrack with side panel type H ("Heavy"), 19" bracket is firmly fixed to side panel (tox-cold welded)

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

Rear horizontal rail for backplane mounting with insulation strip

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Shock and vibration tested to the German "Bahn" standards BN 411002, BN 411003

IP 20, in accordance with IEC 60529

|                          |                      |
|--------------------------|----------------------|
| <b>Materiál:</b>         | Hliník               |
| <b>Povrchová úprava:</b> | Anodized; Passivated |
| <b>Product Type:</b>     | Subrack/Chassis      |
| <b>EMC Shielding:</b>    | Yes                  |

## SPECIFIKACE

Table 1/2


| Katalogové číslo | Rack Height | Hloubka (D) | Množství v balení | For Mounting | Board Depth         | Gasket Type |
|------------------|-------------|-------------|-------------------|--------------|---------------------|-------------|
| 24563-172        | 3U          | 235mm       | 1                 | Backplane    | 160mm, 220mm        | Textile EMC |
| 24563-174        | 3U          | 355mm       | 1                 | Backplane    | 160mm, 220mm, 280mm | Textile EMC |
| 24563-474        | 6U          | 355mm       | 1                 | Backplane    | 160mm, 220mm, 280mm | Textile EMC |
| 24563-173        | 3U          | 295mm       | 1                 | Backplane    | 160mm, 220mm, 280mm | Textile EMC |
| 24563-472        | 6U          | 235mm       | 1                 | Backplane    | 160mm, 220mm        | Textile EMC |
| 24563-473        | 6U          | 295mm       | 1                 | Backplane    | 160mm, 220mm, 280mm | Textile EMC |

Table 2/2

| Katalogové číslo | Shock and Vibration Tolerance | Rukojeť v ceně | Mounting | Complies With   | Rack Width | Static Load |
|------------------|-------------------------------|----------------|----------|-----------------|------------|-------------|
| 24563-172        | 5g (force)                    | No             | Rack     | IEC 60297-3-103 | 84HP       | 15kg        |
| 24563-174        | 5g (force)                    | No             | Rack     | IEC 60297-3-103 | 84HP       | 15kg        |
| 24563-474        | 5g (force)                    | No             | Rack     | IEC 60297-3-103 | 84HP       | 15kg        |
| 24563-173        | 5g (force)                    | No             | Rack     | IEC 60297-3-103 | 84HP       | 15kg        |
| 24563-472        | 5g (force)                    | No             | Rack     | IEC 60297-3-103 | 84HP       | 15kg        |
| 24563-473        | 5g (force)                    | No             | Rack     | IEC 60297-3-103 | 84HP       | 15kg        |

## DALŠÍ PODROBNOSTI O PRODUKTU

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

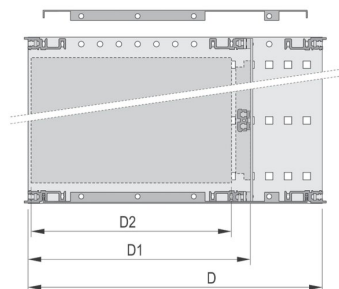

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Naše portfolio silných značek:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**