


EuropacPRO Cover Plate for Bolting to Rugged Side Panel

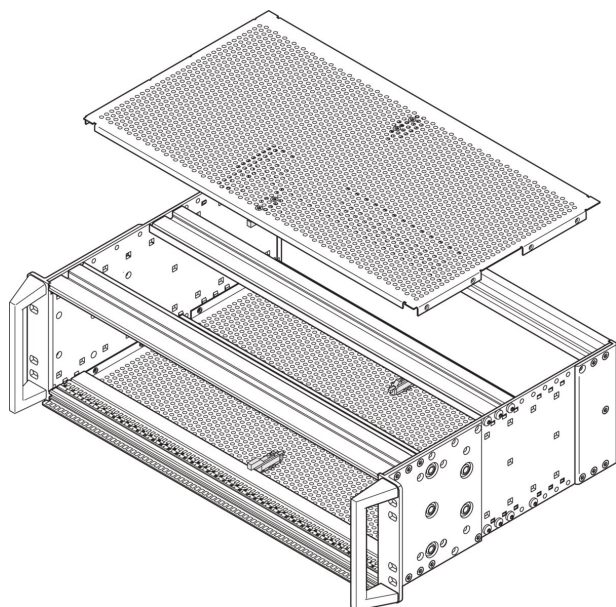

A cover plate is used for electromagnetic shielding or as mechanical protection.

VLASTNOSTI

Perforation degree 58%

Rack Width:	84HP
Materiál:	Hliník
Product Type:	Cover Plate
Produktová řada:	EuropacPRO
Povrchová úprava:	Passivated
Typ:	Perforated
Works With:	Subracks



SPECIFIKACE

Katalogové číslo	Hloubka	Množství v balení	Balení	Torque
24568-004	175mm	2	Pair	2.1N·m
24568-036	277.75mm	2	Pair	2.1N·m
24568-032	275mm	2	Pair	2.1N·m
24568-020	355mm	2	Pair	2.1N·m
24568-016	295mm	2	Pair	2.1N·m
24568-012	295mm	2	Pair	2.1N·m
24568-008	235mm	2	Pair	2.1N·m

DALŠÍ PODROBNOSTI O PRODUKTU

A top cover locking mechanism is optionally available that also fixes the top cover in the front and rear guide rail.

4 stainless steel EMC contact strips per subrack are required for shielding, please order separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE