


Front Panel, Unshielded, Bottom Hinged

Unshielded front panel bottom hinged.

VLASTNOSTI

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

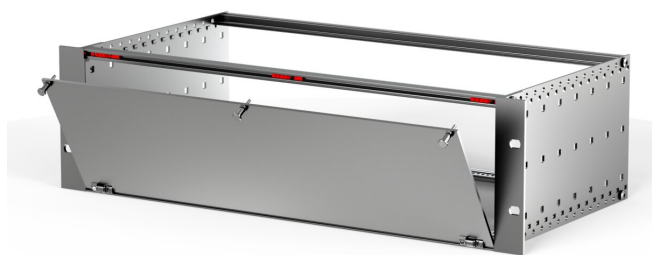

Hĺoubka (D):	2.5mm
Materiál:	Hliník
Povrchová úprava:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel without Handle



SPECIFIKACE

Table 1/2

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Mounting	Front Finish	Rear Finish
20838-280	3U	28HP	1	Hinged, Bottom	Anodized	Conductive
20838-271	3U	42HP	1	Hinged, Bottom	Anodized	Conductive
20838-274	6U	42HP	1	Hinged, Bottom	Anodized	Conductive
20838-279	4U	84HP	1	Hinged, Bottom	Anodized	Conductive
20838-272	3U	63HP	1	Hinged, Bottom	Anodized	Conductive
20838-275	6U	63HP	1	Hinged, Bottom	Anodized	Conductive
20838-278	4U	63HP	1	Hinged, Bottom	Anodized	Conductive
20838-277	4U	42HP	1	Hinged, Bottom	Anodized	Conductive
20838-276	6U	84HP	1	Hinged, Bottom	Anodized	Conductive
20838-273	3U	84HP	1	Hinged, Bottom	Anodized	Conductive


Table 2/2

Katalogové číslo	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)
20838-280	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	141.9mm
20838-271	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	213mm
20838-274	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	213mm
20838-279	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	426.4mm
20838-272	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	319.7mm
20838-275	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	319.7mm
20838-278	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	319.7mm
20838-277	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	213mm
20838-276	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	426.4mm
20838-273	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	426.4mm

DALŠÍ PODROBNOSTI O PRODUKTU

Front panel can be removed in opened position ($> 135^\circ$).

DIAGRAMS

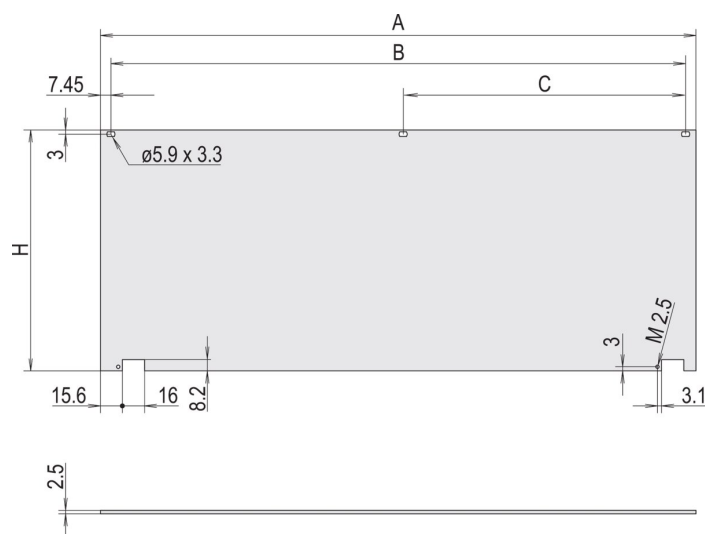

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE