


Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

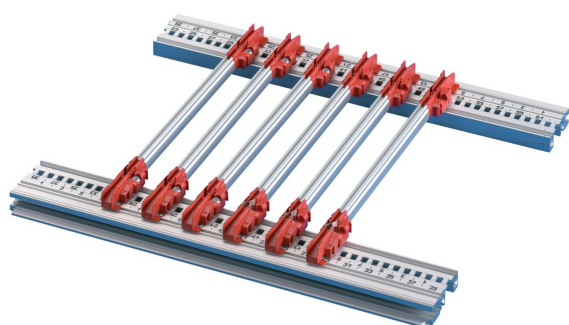

Guide rail mid-piece for individual multi-piece guide rails out of plastic or Aluminum extrusion. Suitable for Standard, Accessory, 4.4" PCB types and end pieces with coding.

VLASTNOSTI

Middle profile for mounting guide rails for 2 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

Produktová řada: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Product Type: Guide Rail
Typ: Middle Section



SPECIFIKACE

Table 1/2

Katalogové číslo	Materiál	Barva	Množství v balení	Board Depth	Groove Width	Kód barvy
34560-891	Hliník	Silver	1	160mm	2	
34560-893	Hliník	Silver	1	280mm	2	
34564-891	PVC	Grey	1	160mm	2	RAL 7035
34564-893	PVC	Grey	1	280mm	2	RAL 7035
34564-900	PVC	Grey	1	1000mm	2	RAL 7035
34564-892	PVC	Grey	1	220mm	2	RAL 7035
34560-900	Hliník	Silver	1	1000mm	2	
34560-892	Hliník	Silver	1	220mm	2	

Table 2/2

Katalogové číslo	Povrchová úprava	Works With
34560-891	Anodized	Subracks, Cases, Chassis
34560-893	Anodized	Subracks, Cases, Chassis
34564-891		Subracks, Cases, Chassis
34564-893		Subracks, Cases, Chassis
34564-900		Subracks, Cases, Chassis
34564-892		Subracks, Cases, Chassis
34560-900	Anodized	Subracks, Cases, Chassis
34560-892	Anodized	Subracks, Cases, Chassis

DALŠÍ PODROBNOSTI O PRODUKTU

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE