


Panhead Screw, Torx, Self-Securing

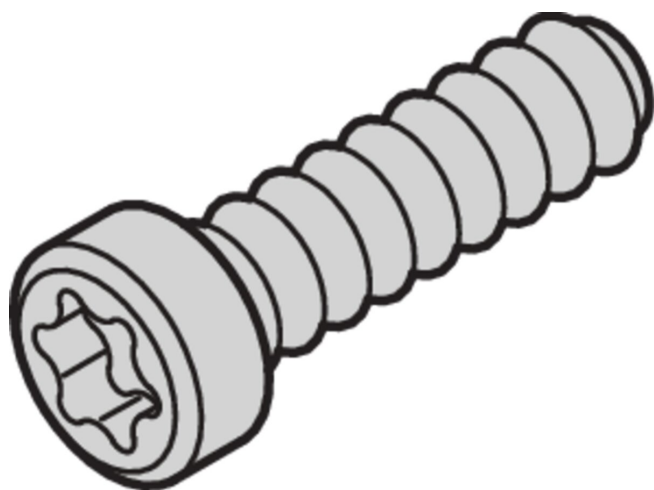

Good compromise between profile height and bearing area. Better load distribution than round heads. Compatible with automated assembly. Partially coated thread to prevent the screw from loosening on its own due to vibrations

Panhead Screw, Torx, St, zinc plated, M2.5 x 6 (Partially coated thread to prevent the screw from loosening on its own due to vibrations).

VLASTNOSTI

Torx imprint bears greater torque

The star-shaped head prevents cam-out

Typ: Panhead Screw
Product Type: Screw
Materiál: Ocel



SPECIFIKACE

Katalogové číslo	Length	Povrchová úprava	Množství v balení	Thread Size	Works With
24560-159	6mm	Pozinkovaná Ocel	100	M2.5	Backplanes, Test Adapters
21500-039	9.3mm	Pozinkovaná Ocel	100	M2.5	Front Panels, Horizontal Rails, Type H, Horizontal Rails, Type R

DALŠÍ PODROBNOSTI O PRODUKTU

Torque max. 0.2 Nm.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE