

nVent CADDY EZ Riser



The nVent CADDY EZ Riser is a multi-purpose clamp designed to secure and support vertical pipe runs. This unified solution can be installed in several approved orientations and serves as a standard, standoff, or close-quarters riser—effectively functioning as three clamps in one. Ready-to-use out of the box, the nVent CADDY EZ Riser features pre-drilled threaded rod holes for standoff installations and score marks for simple ear removal in spaces where full-sized riser clamps do not fit.

Contractors can enjoy simplified material handling with a multi-functional clamp that allows for various orientations and retains listing even when ears are removed.

FUNKTIONER

Only one tool needed to tighten due to serrated wash-heads

Installs up to 60% faster than standard riser clamps

Integrated second set of bolt holes allow the assembly to adapt from a riser clamp into a stand-off support easily

No need to stock and use separate part families for standard and close-quarter clamps to offer a full range of listed parts

Conforms with Federal Specification WW-H-171 (Type 8), Manufacturers Standardization Society (MSS) SP-58 (Type 8)

Finish: Electrogalvanized
Materiale: Stål



SPECIFIKATIONER

Katalognummer	Artikelnummer	Outer Diameter (OD)	Hole Size (HS)	A	B	C	Static Load
EZR0250	179231	73 mm	9.9 mm	279.4 mm	190.5 mm	25.4 mm	1735N
EZR0300	179232	88.9 mm	9.9 mm	298.5 mm	206.4 mm	25.4 mm	2400N
EZR0200	179230	60.3 mm	9.9 mm	260.4 mm	177.8 mm	25.4 mm	1100N
EZR0050	179225	21.3 mm	9.9 mm	215.9 mm	130.2 mm	22.2 mm	1100N
EZR0150	179229	48.3 mm	9.9 mm	250.8 mm	158.8 mm	22.2 mm	1100N
EZR0125	179228	42.2 mm	9.9 mm	241.3 mm	152.4 mm	22.2 mm	1100N



Katalognummer	Artikelnummer	Outer Diameter (OD)	Hole Size (HS)	A	B	C	Static Load
EZR0100	179227	33.4 mm	9.9 mm	228.6 mm	142.9 mm	22.2 mm	1100N
EZR0075	179226	26.7 mm	9.9 mm	228.6 mm	136.5 mm	22.2 mm	1100N
EZR0500	179235	141.3 mm	13.2 mm	368.3 mm	298.5 mm	38.1 mm	5200N
EZR0600	179236	168.3 mm	13.2 mm	406.4 mm	323.9 mm	38.1 mm	6900N
EZR0400	179234	114.3 mm	13.2 mm	330.2 mm	254 mm	31.8 mm	3600N

YDERLIGERE PRODUKTOPLYSNINGER

Clamp is fitted for steel pipe and should be installed below a coupling or shear lug, with bolts torqued to recommended value.

Use of a socket or driver is recommended for installation.

DIAGRAMS

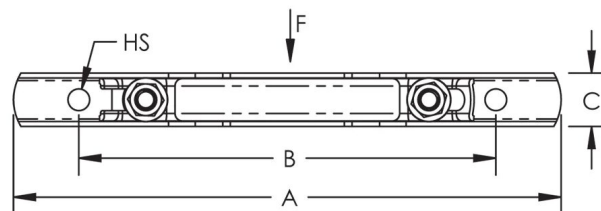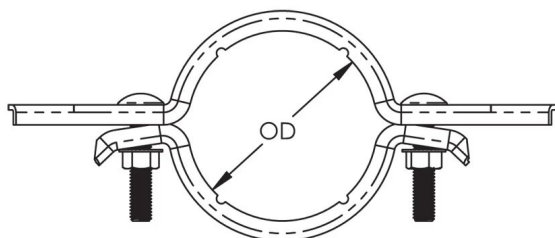

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

