


nVent CADDY Pyramid Equipment Support Kit, 4 Post Base

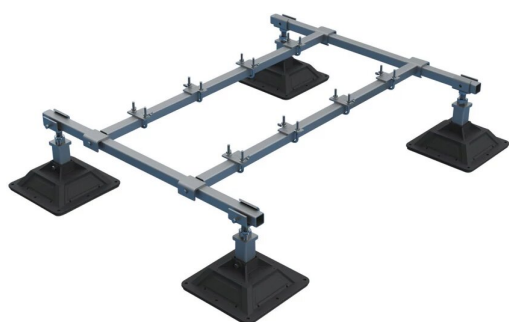

FUNKTIONER

Kit includes post-base assemblies, frame and equipment-support clamps

Assembles and adjusts to size and height in minutes by one person with one tool

Innovative crossbar and equipment-support clamps enable quick assembly

Integral foam pad provides gentle interface for all roof types

Hot-dip galvanized and UV stabilized for long lasting performance

Assembled support can be lifted as one unit and easily relocated



SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Finish	Temperatur e	Height (H)	Length (L)
PEK4B	360426	Stål, Polypropylene, Polyethylen	Hot-Dip Galvanized	-34 to 54.4 °C	305 - 457 mm	1257mm

Table 2/3

Katalognummer	Artikelnummer	Post Base (A)	Square Tube (B)	Cross Bar Assembly (C)	Width (W)	Surface Area
PEK4B	360426	314 mm x 4 pc	1067 mm x 2 pc	1232 mm x 2 pc	1588 mm	0.36m ²



Table 3/3

Katalognummer	Artikelnummer	Unit Weight	Ultimate Static Load (F)	Static Load Safety Factor
PEK4B	360426	36 kg	4980N	3:1

YDERLIGERE PRODUKTOPLYSNINGER

Static load must be stable and uniformly distributed across frame.

DIAGRAMS

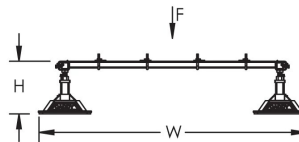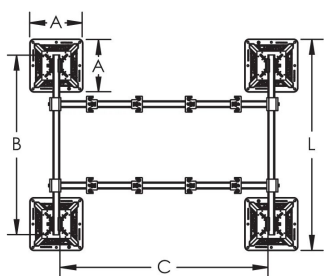

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

