

nVent CADDY Pyramid ST Adjustable Strut Support



FUNKTIONER

Height adjustability provides effective navigation of pipe, conduit, duct and cable tray around obstructions

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Ready to use out of the box, saving installation time and labor

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Hot-dip galvanized and UV stabilized for long lasting performance

Static Load Safety Factor:	3:1
Temperature:	-45 to 65 °C
Finish:	Hot-Dip Galvanized
Materiale:	Polyethylen;Polypropylene;Stål



SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Length 1 (L1)	Length 2 (L2)	Height (H)	Width (W)	Surface Area
PSA10CH13	360468	254 mm	317.5 mm	152 - 330 mm	203 mm	59355mm ²
PSA16AH18	360469	406 mm	483 mm	178 - 457 mm	203 mm	91613mm ²

Table 2/2

Katalognummer	Artikelnummer	Unit Weight	Static Load
PSA10CH13	360468	2 kg	4450N
PSA16AH18	360469	3 kg	6670N

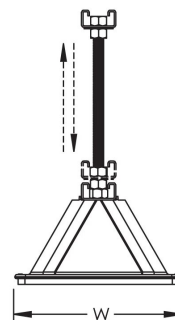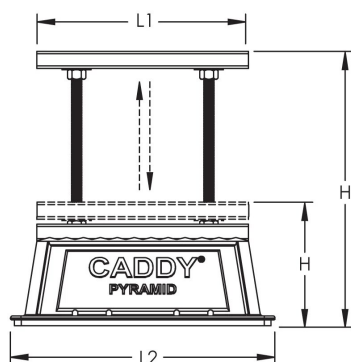

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

