


# nVent CADDY Pyramid ST Bridge Assembly

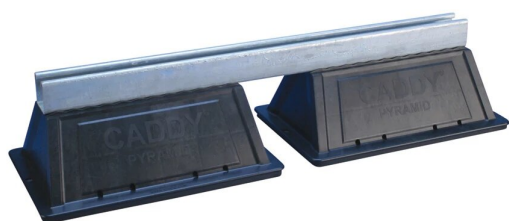

## FUNKTIONER

Ideal for supporting multiple pipe runs, cable tray and air handling units

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Ready to use out of the box, saving installation time and labor

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Hot-dip galvanized and UV stabilized for long lasting performance

|                                   |                                |
|-----------------------------------|--------------------------------|
| <b>Static Load Safety Factor:</b> | 3:1                            |
| <b>Temperature:</b>               | -45 to 65 °C                   |
| <b>Finish:</b>                    | Hot-Dip Galvanized             |
| <b>Materiale:</b>                 | Polyethylen;Polypropylene;Stål |

## SPECIFIKATIONER

Table 1/2



| Katalognummer | Artikelnummer | Length 1 (L1) | Length 2 (L2) | Height (H) | Width (W) | Surface Area          |
|---------------|---------------|---------------|---------------|------------|-----------|-----------------------|
| PSB24A        | 360475        | 610 mm        | 673 mm        | 142 mm     | 203 mm    | 118709mm <sup>2</sup> |
| PSB42A        | 360478        | 1067 mm       | 1143 mm       | 142 mm     | 203 mm    | 183225mm <sup>2</sup> |

Table 2/2

| Katalognummer | Artikelnummer | Unit Weight | Static Load |
|---------------|---------------|-------------|-------------|
| PSB24A        | 360475        | 2 kg        | 8900N       |
| PSB42A        | 360478        | 4 kg        | 13340N      |

## YDERLIGERE PRODUKTOPLYSNINGER

Static loads are assumed to be uniformly distributed.

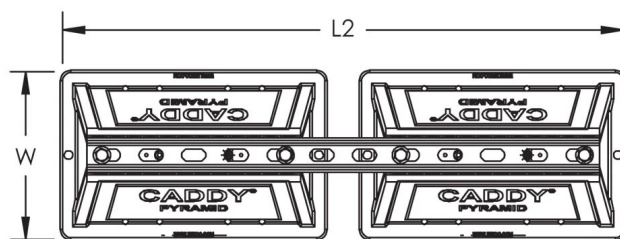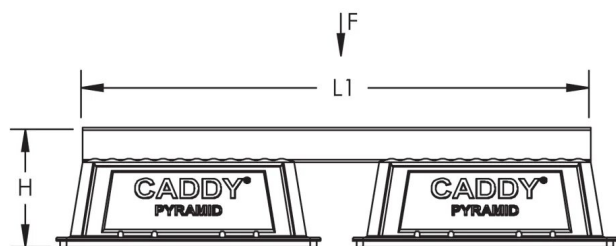

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

