

nVent CADDY Self-Cutting Cable Tie



The nVent CADDY Self-Cutting Cable Tie is a versatile, tool-free datacom solution for bundling large amounts of cables. This simple, yet innovative product features a built-in cutting blade to ensure a secure fastening and a safe, clean tie-off finish. Made from durable 6/6 nylon, the Self-Cutting Cable Tie boasts a robust 50lb/ 22Kg of tensile strength.

FUNKTIONER

Eliminates sharp edges and protects exposed skin from cuts during installation

Lock and twist to cut, no cutting tools required

Different colors including a black UV-protected version to meet specific needs

RoHS (Restriction of Hazardous Substances Directive) compliant

Halogen free

cULus Listed to UL 62275/CSA C22.2 No. 62275, UL Certified to IEC 62275

Complies With: IEC® 60695-2-11 (Glow Wire Test 960 °C)





SPECIFIKATIONER

Katalognummer	Artikelnummer	Materiale	Farve	Length (L)	Width (W)	Installation Temperature	Driftstemperatur
CADTIESC14CBAP	601009	Nylon, Stainless Steel 301 (EN 1.4310)	Black	355.6m m	4.32 mm	0 °C Min	-20 to 85 °C
CADTIESC8CBAP	601018	Nylon, Stainless Steel 301 (EN 1.4310)	Black	203.2m m	4.32 mm	0 °C Min	-20 to 85 °C
CADTIESC8CNAP	601019	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	203.2m m	4.32 mm	0 °C Min	-20 to 85 °C
CADTIESC11CBAP	601000	Nylon, Stainless Steel 301 (EN 1.4310)	Black	279.4m m	4.32 mm	0 °C Min	-20 to 85 °C

Katalognummer	Artikelnummer	Materiale	Farve	Length (L)	Width (W)	Installation Temperature	Driftstemperatur
CADTIESC11CNAP	601001	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	279.4m	4.32 mm	0 °C Min	-20 to 85 °C
CADTIESC14CNAP	601010	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	355.6m	4.32 mm	0 °C Min	-20 to 85 °C

DIAGRAMS

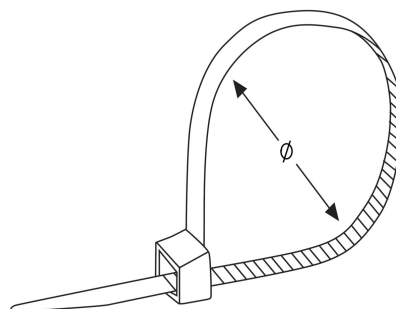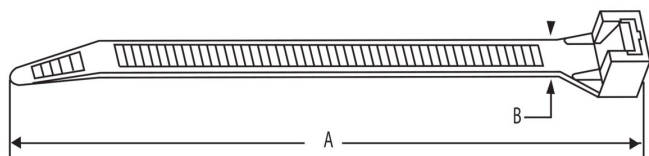

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

