

Mesh Bonding Network Connector, MBNC82



FUNKTIONER

Allows for fast, simple and economical field connection of grounding and bonding wires

Heavy duty clamps with stainless steel hardware are suitable for direct burial


Can accommodate additional pigtails that can be used to connect to building steel and equipment

Can be combined with Universal Pedestal Clamp for bonding to various pedestal sizes for mesh bonding networks



SPECIFIKATIONER

Katalognummer	Materiale	Conductor Size
MBNC82	Bronze, Stainless Steel 304 (EN 1.4301)	#8 Solid - #2 Stranded, 10 mm ² Solid - 35 mm ² Stranded

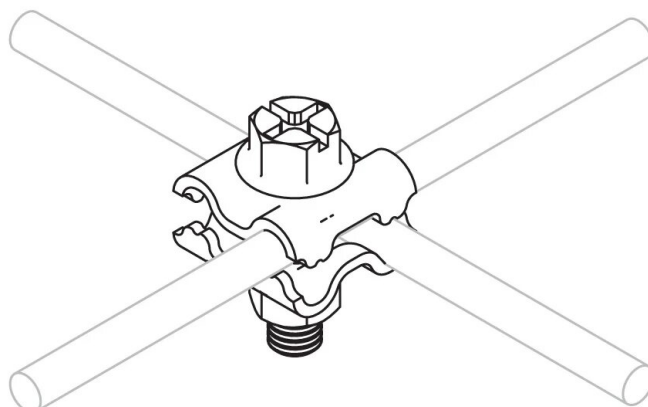

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE