

nVent ERICO Ericore Unterminated Conductor



FUNKTIONER

Low-inductance, low-impedance cable designed to minimize voltage build-up due to lightning impulses

Multiple insulated layers of conductor reduce the potential of side flashing

Requires upper and lower termination kits

SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Length (L)	Length	Length (L)	Length	Capacitance
ERICORE	701875	1m	1 m	1m	1 m	0.75 nF

Table 2/3

Katalognummer	Artikelnummer	Cross Section	Cross Section	Diameter (Ø)	Impedance	Inductance
ERICORE	701875	50mm ²	50mm ²	36 mm	12 Ω Max	37nH


Table 3/3

Katalognummer	Artikelnummer	Resistance (Rdc)	Resistance (Rimp)	Unit Weight
ERICORE	701875	0.5mΩ·m	6mΩ·m	1.18 kg

YDERLIGERE PRODUKTOPLYSNINGER

Consult nVent ERICO technical support or the installation manual for guidance on maximum allowable lengths.

Inductance and Capacitance are per meter.

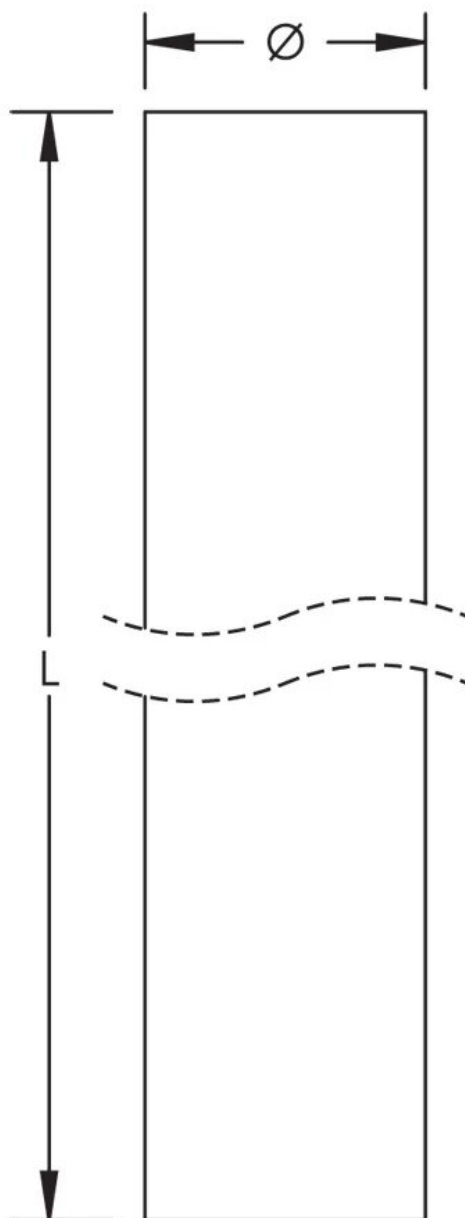

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE