

PDR Perforated Symmetric Profile



FUNKTIONER

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

RoHS compliant

Conforms to EN 60715 and 50022 and DIN 46277

Finish: Electrogalvanized

Materiale: Stål



SPECIFIKATIONER

Table 1/2


Katalognummer	Artikelnummer	Height (H)	Width (W)	Length (L)	Thickness (T)	A
PDR7-3M	557860	35 mm	7.5 mm	3000mm	1 mm	4 mm
PDR5-2M	557750	15 mm	5.5 mm	2000mm	1 mm	2.25 mm
PDR7-2M	557850	35 mm	7.5 mm	2000mm	1 mm	4 mm
PDR7-2M-5-2	557855	35 mm	7.5 mm	2000mm	1 mm	4 mm
PDR15-3M	557960	35 mm	15 mm	3000mm	1.5 mm	4 mm
PDR15-2M	557950	35 mm	15 mm	2000mm	1.5 mm	4 mm

Table 2/2

Katalognummer	Artikelnummer	B	C	D	Unit Weight
PDR7-3M	557860	7 mm	18 mm	6.2 mm	0.92 kg
PDR5-2M	557750	7.8 mm	12.2 mm	4.2 mm	0.28 kg
PDR7-2M	557850	7 mm	18 mm	6.2 mm	0.62 kg
PDR7-2M-5-2	557855	11 mm	25 mm	5.2 mm	0.62 kg

Katalognummer	Artikelnummer	B	C	D	Unit Weight
PDR15-3M	557960	7 mm	18 mm	6.2 mm	1.81 kg
PDR15-2M	557950	7 mm	18 mm	6.2 mm	1.2 kg

DIAGRAMS

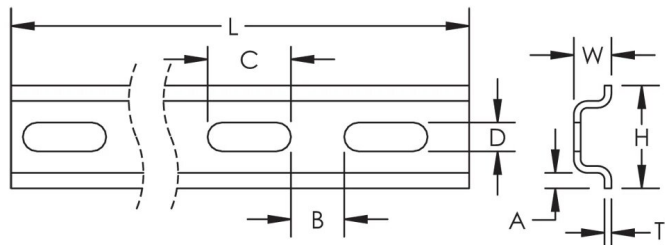

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE