


CFF Tapered Screw-In Plug for A12, A22 and A32K Couplers

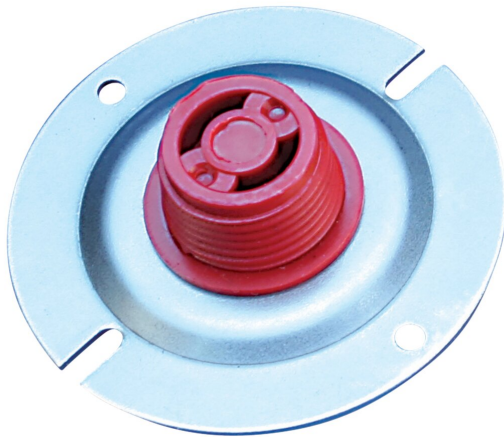

FUNKTIONER

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

Materiale: High Density Polyethylene (HDPE);Stål

SPECIFIKATIONER

Table 1/2


Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL28CFF	153900	28 mm	#9	30M	75 mm	18 mm
EL30CFF	153910	30 mm			75 mm	18 mm
EL50CFF	154980	50 mm			95 mm	18 mm
EL22CFF	153880	22 mm	#7		75 mm	18 mm
EL32CFF	153920	32 mm	#10		95 mm	18 mm
EL36CFF	153925	36 mm	#11	35M	95 mm	18 mm
EL25CFF	153890	25 mm	#8	25M	75 mm	18 mm
EL40CFF	153930	40 mm			95 mm	18 mm

Table 2/2

Katalognummer	Artikelnummer	Farve	Pakke mængde
EL28CFF	153900	Black	25

Katalognummer	Artikelnummer	Farve	Pakke mængde
EL30CFF	153910	White	25
EL50CFF	154980	Black	15
EL22CFF	153880	Blue	25
EL32CFF	153920	Yellow	15
EL36CFF	153925	Blue	15
EL25CFF	153890	Red	25
EL40CFF	153930	Green	15

DIAGRAMS

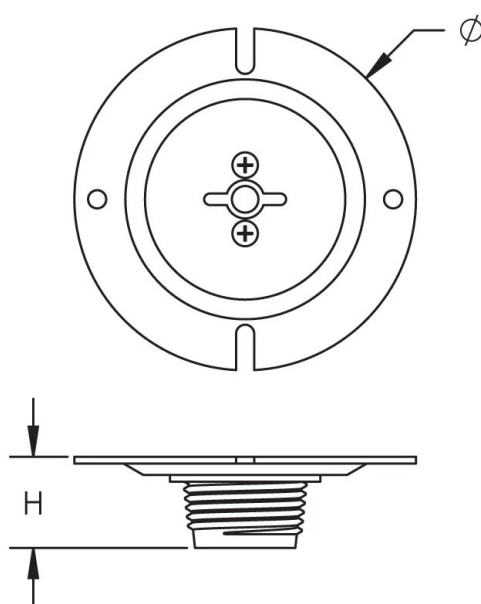

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE