

CFFP Tapered Plastic Screw-In Plug for A12, A22 and A32K Couplers



FUNKTIONER

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

Materiale: Polyethylen

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL28CFFP	156070	28 mm	#9	30M	59 mm	23 mm
EL12CFFP	156010	12 mm	#4	10M	59 mm	23 mm
EL25CFFP	156060	25 mm	#8	25M	59 mm	23 mm
EL20CFFP	156050	20 mm	#6	20M	59 mm	23 mm
EL14CFFP	156020	14 mm			59 mm	23 mm
EL16CFFP	156030	16 mm	#5	15M	59 mm	23 mm

Table 2/2


Katalognummer	Artikelnummer	Farve	Pakke mængde
EL28CFFP	156070	Black	100
EL12CFFP	156010	Red	100
EL25CFFP	156060	Red	100

Katalognummer	Artikelnummer	Farve	Pakke mængde
EL20CFFP	156050	Yellow	100
EL14CFFP	156020	Green	100
EL16CFFP	156030	Black	100

YDERLIGERE PRODUKTOPLYSNINGER

EL12CFFP and EL16CFFP can also be used on the A2 coupler families.

DIAGRAMS

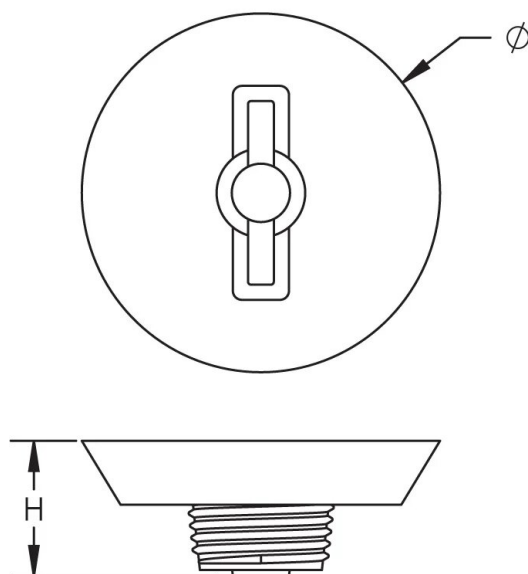

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE