

CPP Tapered Plastic Screw-In Plug for A12, A22 and A32K



FUNKTIONER

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

Materiale: High Density Polyethylene (HDPE)

SPECIFIKATIONER


Table 1/2

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL16CPPB100	153090	16 mm	#5	15M	22 mm	13 mm
EL14CPPB100	153080	14 mm			22 mm	13 mm
EL10CPPB100	153060	10 mm	#3		17 mm	13 mm
EL18CPPB100	153100	18 mm			27 mm	13 mm
EL12CPPB100	153070	12 mm	#4	10M	17 mm	13 mm
EL20CPPB100	153110	20 mm	#6	20M	27 mm	13 mm
EL25CPPB100	153130	25 mm	#8	25M	33 mm	16 mm
EL36CPPB50	153180	36 mm	#11	35M	46 mm	16 mm
EL32CPPB100	153160	32 mm	#10		42 mm	16 mm
EL30CPPB100	153150	30 mm			37 mm	16 mm
EL40CPPB50	153200	40 mm			52 mm	16 mm

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL28CPPB100	153140	28 mm	#9	30M	37 mm	16 mm
EL22CPPB100	153120	22 mm	#7		33 mm	16 mm
EL50CPPB40	153220	50 mm			64 mm	16 mm

Table 2/2				
Katalognummer	Artikelnummer	Farve	Pakke mængde	
EL16CPPB100	153090	Black	100	
EL14CPPB100	153080	Green	100	
EL10CPPB100	153060	Yellow	100	
EL18CPPB100	153100	White	100	
EL12CPPB100	153070	Red	100	
EL20CPPB100	153110	Yellow	100	
EL25CPPB100	153130	Red	100	
EL36CPPB50	153180	Blue	50	
EL32CPPB100	153160	Yellow	100	
EL30CPPB100	153150	White	100	
EL40CPPB50	153200	Green	50	
EL28CPPB100	153140	Black	100	
EL22CPPB100	153120	Blue	100	
EL50CPPB40	153220	Black	40	

DIAGRAMS

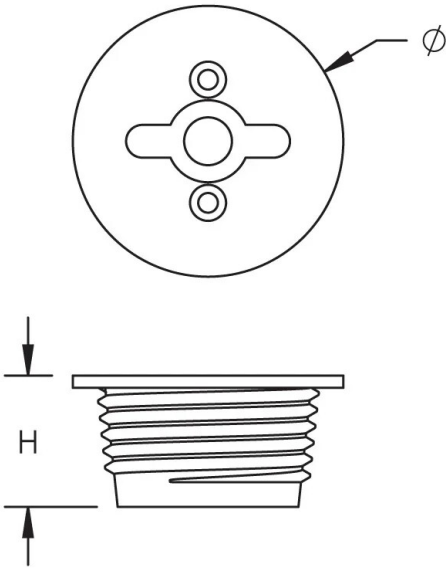

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE