

CPPS Tapered Plastic Screw-In Plug with Steel Cap for A12



FUNKTIONER

Designed for use with the A12 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Steel cap provides added protection from damage

Color coded for the appropriate coupler size

Materiale: High Density Polyethylene (HDPE);Stål

SPECIFIKATIONER


Table 1/2

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL14CPPS	153620	14 mm			22 mm	15 mm
EL12CPPS	153610	12 mm	#4	10M	17 mm	15 mm
EL18CPPS	153640	18 mm			27 mm	15 mm
EL10CPPS	153600	10 mm	#3		17 mm	15 mm
EL16CPPS	153630	16 mm	#5	15M	22 mm	15 mm
EL20CPPS	153650	20 mm	#6	20M	27 mm	15 mm
EL30CPPS	153690	30 mm			37 mm	18 mm
EL50TCPPS	154970	50 mm			64 mm	18 mm
EL28CPPS	153680	28 mm	#9	30M	37 mm	18 mm
EL25CPPS	153670	25 mm	#8	25M	33 mm	18 mm
EL40CPPS	153710	40 mm			52 mm	18 mm

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL22CPPS	153660	22 mm	#7		33 mm	18 mm
EL32CPPS	153700	32 mm	#10		42 mm	18 mm

Table 2/2			
Katalognummer	Artikelnummer	Farve	Pakke mængde
EL14CPPS	153620	Green	100
EL12CPPS	153610	Red	100
EL18CPPS	153640	White	100
EL10CPPS	153600	Yellow	100
EL16CPPS	153630	Black	100
EL20CPPS	153650	Yellow	100
EL30CPPS	153690	White	100
EL50TCPPS	154970	Black	40
EL28CPPS	153680	Black	100
EL25CPPS	153670	Red	100
EL40CPPS	153710	Green	50
EL22CPPS	153660	Blue	100
EL32CPPS	153700	Yellow	100

DIAGRAMS

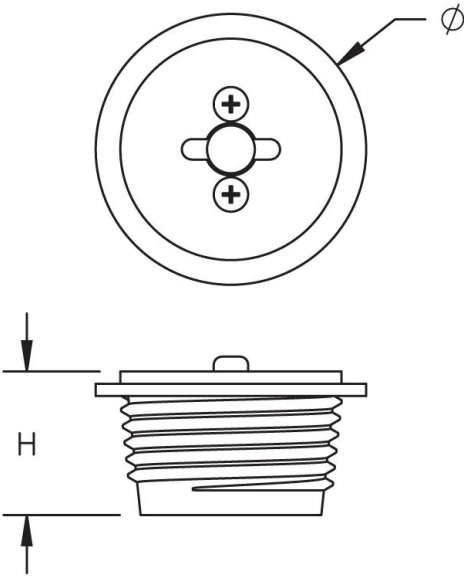

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE