


Countersunk Screw

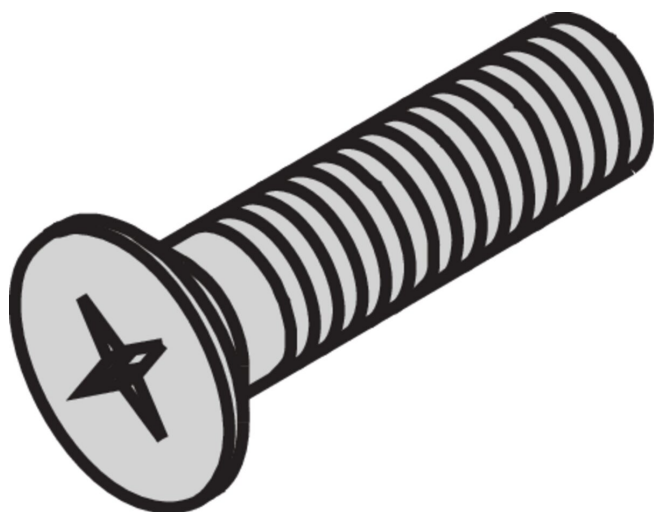

Flush surface, no interference with sliding parts. Self-centering in precision countersink. Clean external geometry (important for hygiene or airflow).

FUNKTIONER

Countersunk screws are used for numerous mounting options in a subrack or desktop case.

Cross Recess imprint offers a high level of torque to achieve quick and easy installation

Torx imprint bears greater torque

The Torx star-shaped head prevents cam-out

Product Type: Screw



SPECIFIKATIONER

Table 1/2

Katalognummer	Length	Materiale	Finish	Pakke mængde	Thread Size	Højde
24560-139	5mm	Stål	Forzinket Stål	100	M4	
24560-183	12mm	Stål	Forzinket Stål	100	M5	
24560-182	12mm	Stål	Forzinket Stål	4	M5	
24560-145	14mm	Stål	Forzinket Stål	100	M4	
24560-164	8mm	Stål	Nickel Plated	100	M2.5	4.7mm
24560-158	7.7mm	Stål	Forzinket Stål	100	M2.5	
21100-542	8mm	Stål	Nickel Plated	100	M3	
21100-429	8mm	Stål	Nickel Plated	100	M2.5	
21100-649	10mm	Stål	Forzinket Stål	100	M2.5	
21100-500	10mm	Stål	Nickel Plated	100	M2.5	
21100-507	12mm	Stål	Nickel Plated	100	M2.5	

Table 2/2

Katalognummer	Type	Bredde	Works With	Thread Type	Torque
24560-139	Countersunk Screw		Front Panels		1.3N·m

Katalognummer	Type	Bredde	Works With	Thread Type	Torque
24560-183	Countersunk Screw		Front Panels		2.4N·m
24560-182	Countersunk Screw		Front Panels		2.4N·m
24560-145	Countersunk Screw		Front Panels		2.4N·m
24560-164	Countersunk Screw	4.7mm	Front Panels	Metric	
24560-158	Countersunk Screw		Front Panels		
21100-542	Screw		Front Panels		
21100-429	Screw		Front Panels		
21100-649	Screw		Front Panels		
21100-500	Screw		Front Panels		
21100-507	Screw		Front Panels		

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE