


Front Panel, Refrofit Shielding, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

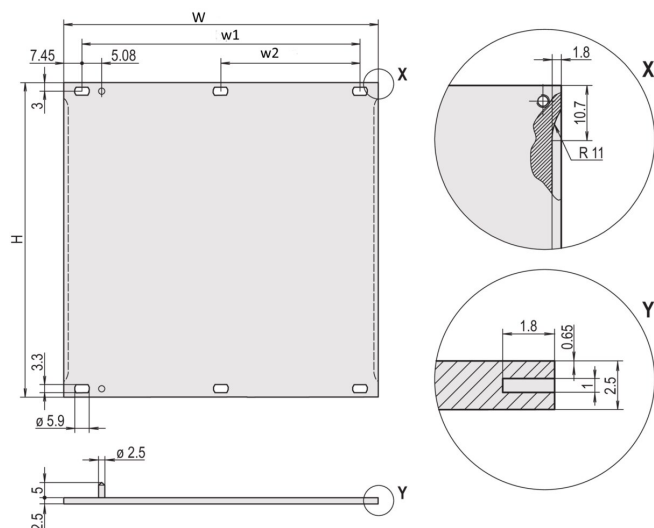

KATALOGNUMMER

30846-676

Flat front panel. Shieldable with stainless steel EMC gasket.

FUNKTIONER

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive



PRODUKTEGENSKABER

Rack Height: 3U

Rack Width: 84HP

Pakke mængde: 1

Accessory Type: Front panel

Mounting: Screw-on Front

Gasket Type: Stainless Steel EMC

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Dybde (D): 2.5mm

EMC Shielding: No (Retrofittable)

Finish: Anodized; Passivated

Højde (H): 128.4mm

Materiale: Aluminium

