

EuropacPRO 19" Subrack Kit for Backplane, Shielded

EMC Shielded subrack for backplane mounting, rear side covered by a rear panel.



FUNKTIONER

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

IP 20, in accordance with IEC 60529

Aluminum construction

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rail for backplane mounting with insulation strip

Horizontal rail type "light"

Materiale:	Aluminium
Finish:	Anodized; Passivated
Product Type:	Subrack/Chassis
EMC Shielding:	Yes

SPECIFIKATIONER

Table 1/2


Katalognummer	Rack Height	Dybde (D)	Pakke mængde	For Mounting	Board Depth	Gasket Type
24563-144	3U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-145	3U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-146	3U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-143	3U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-442	6U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-443	6U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-444	6U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-445	6U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-142	3U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-446	6U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC

Table 2/2

Katalognummer	Håndtag inkluderet	Mounting	Complies With	Rack Width	Static Load
24563-144	No	Rack	IEC 60297-3-103	84HP	11kg
24563-145	No	Rack	IEC 60297-3-103	84HP	11kg
24563-146	No	Rack	IEC 60297-3-103	84HP	11kg
24563-143	No	Rack	IEC 60297-3-103	84HP	11kg
24563-442	No	Rack	IEC 60297-3-103	84HP	11kg
24563-443	No	Rack	IEC 60297-3-103	84HP	11kg
24563-444	No	Rack	IEC 60297-3-103	84HP	11kg
24563-445	No	Rack	IEC 60297-3-103	84HP	11kg
24563-142	No	Rack	IEC 60297-3-103	84HP	11kg
24563-446	No	Rack	IEC 60297-3-103	84HP	11kg

YDERLIGERE PRODUKTOPLYSNINGER

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

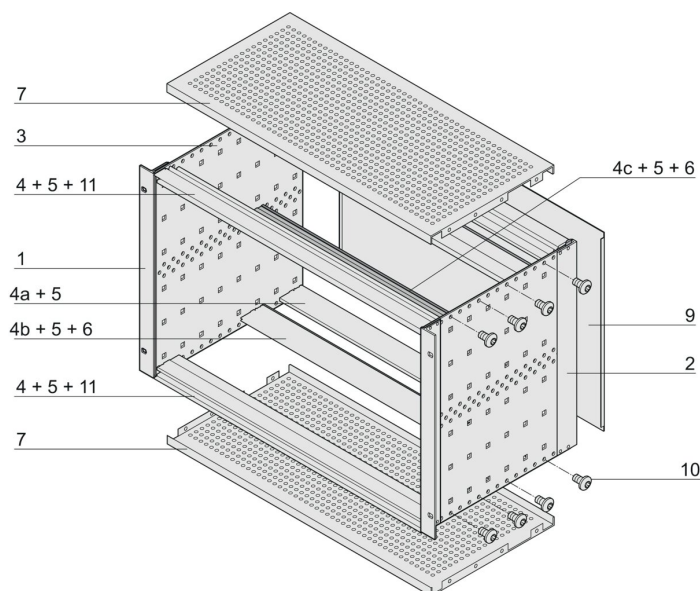

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE