


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

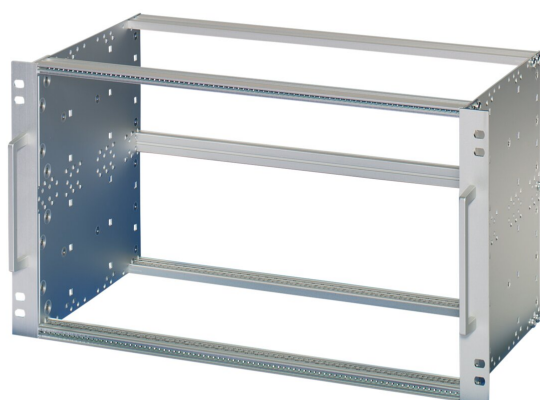

FUNKTIONER

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additionally safety (NFF standard)

Supplied as space-saving flat-pack

Static Load: 15kg
Materiale: Aluminium
EMC Shielding: No
Product Type: Subrack/Chassis



SPECIFIKATIONER

Table 1/2

Katalognummer	Rack Height	Dybde	Pakke mængde	For Mounting	Board Depth	Gasket Type
21500-077	3U	235mm	1	Backplane	220mm	Textile EMC

Katalognummer	Rack Height	Dybde	Pakke mængde	For Mounting	Board Depth	Gasket Type
21500-078	6U	235mm	1	Backplane	220mm	Textile EMC

Table 2/2

Katalognummer	Shock and Vibration Tolerance	Håndtag inkluderet	Mounting	Complies With	Finish	Rack Width
21500-077	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP
21500-078	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP

YDERLIGERE PRODUKTOPLYSNINGER

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE