


# EuropacPRO Advanced EMC Side Panel Cover

Aluminium Side panel 3mm to increase the EMC shielding effect of the subrack by covering the not needed cut-outs.

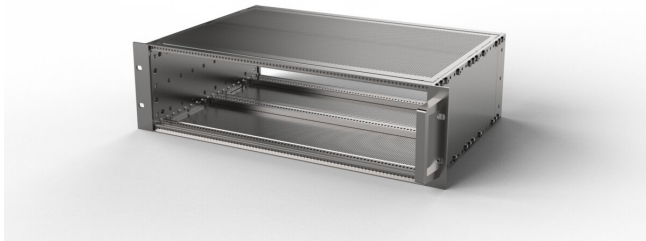

## FUNKTIONER

Side panel covers for increased lateral RF shielding

Assembled on the outside of the standard side panel

Assembly material included

|                        |            |
|------------------------|------------|
| <b>Materiale:</b>      | Aluminium  |
| <b>Produktfamilie:</b> | EuropacPRO |
| <b>Finish:</b>         | Passivated |
| <b>Product Type:</b>   | Side Panel |
| <b>Works With:</b>     | Subracks   |
| <b>Type:</b>           | Type H     |
| <b>EMC Shielding:</b>  | Yes        |



## SPECIFIKATIONER

Table 1/2

| Katalognummer | Rack Height | Dybde    | Pakke mængde | Length   | Pakkeenhed |
|---------------|-------------|----------|--------------|----------|------------|
| 24563-256     | 3U          | 235mm    | 2            | 235mm    | Pair       |
| 24563-268     | 4U          | 355mm    | 2            | 355mm    | Pair       |
| 24563-257     | 3U          | 275mm    | 2            | 275mm    | Pair       |
| 24563-269     | 4U          | 415mm    | 2            | 415mm    | Pair       |
| 24563-267     | 4U          | 295mm    | 2            | 295mm    | Pair       |
| 24563-266     | 4U          | 235mm    | 2            | 235mm    | Pair       |
| 24563-270     | 4U          | 495mm    | 2            | 495mm    | Pair       |
| 24563-265     | 4U          | 175mm    | 2            | 175mm    | Pair       |
| 24563-275     | 6U          | 175mm    | 2            | 175mm    | Pair       |
| 24563-258     | 3U          | 277.75mm | 2            | 277.75mm | Pair       |
| 24563-276     | 6U          | 235mm    | 2            | 235mm    | Pair       |
| 24563-262     | 3U          | 495mm    | 2            | 495mm    | Pair       |
| 24563-277     | 6U          | 275mm    | 2            | 275mm    | Pair       |

| Katalognummer | Rack Height | Dybde    | Pakke mængde | Length   | Pakkeenhed |
|---------------|-------------|----------|--------------|----------|------------|
| 24563-261     | 3U          | 415mm    | 2            | 415mm    | Pair       |
| 24563-278     | 6U          | 277.75mm | 2            | 277.75mm | Pair       |
| 24563-279     | 6U          | 295mm    | 2            | 295mm    | Pair       |
| 24563-260     | 3U          | 355mm    | 2            | 355mm    | Pair       |
| 24563-280     | 6U          | 355mm    | 2            | 355mm    | Pair       |
| 24563-281     | 6U          | 415mm    | 2            | 415mm    | Pair       |
| 24563-259     | 3U          | 295mm    | 2            | 295mm    | Pair       |

Table 2/2

| Katalognummer | Rack Height | Dybde | Pakke mængde | Length | Pakkeenhed |
|---------------|-------------|-------|--------------|--------|------------|
| 24563-282     | 6U          | 495mm | 2            | 495mm  | Pair       |
| 24563-255     | 3U          | 175mm | 2            | 175mm  | Pair       |

## YDERLIGERE PRODUKTOPLYSNINGER

Side panel and 19" bracket are tox-cold welded together. toxen = Clinching technique, without add aids. This takes place with special tools and high pressure.

9 U version available on request.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**