


# EuropacPRO Mounting Plate for Use With Cover Plate

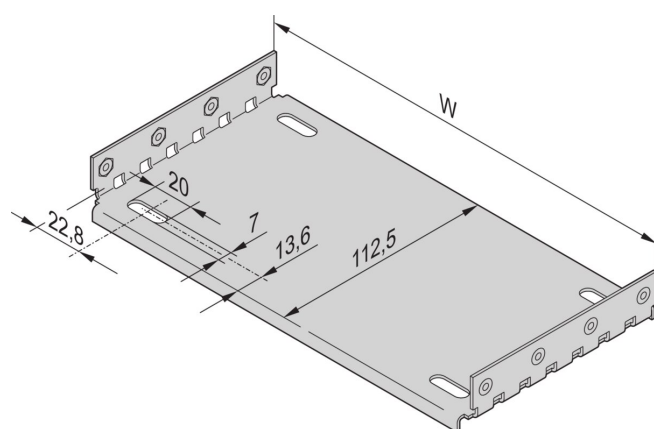

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

## FUNKTIONER

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

**Materiale:** Aluminium  
**Produktfamilie:** EuropacPRO  
**Product Type:** Mounting Plate  
**Works With:** Subracks



## SPECIFIKATIONER

| Katalognummer | Rack Width | Pakke mængde | Dybde   | Bredde   | Certificeringer |
|---------------|------------|--------------|---------|----------|-----------------|
| 34563-004     | 84HP       | 1            | 112.5mm | 431.35mm | RoHS            |
| 34563-019     | 63HP       | 1            | 172.5mm | 324.67mm | RoHS            |
| 34563-014     | 42HP       | 1            | 172.5mm | 217.99mm | RoHS            |
| 34563-009     | 28HP       | 1            | 172.5mm | 146.88mm | RoHS            |
| 34563-003     | 63HP       | 1            | 112.5mm | 324.67mm | RoHS            |
| 34563-002     | 42HP       | 1            | 112.5mm | 217.99mm | RoHS            |

| Katalognummer | Rack Width | Pakke mængde | Dybde   | Bredde   | Certificeringer |
|---------------|------------|--------------|---------|----------|-----------------|
| 34563-001     | 28HP       | 1            | 112.5mm | 146.88mm | RoHS            |
| 34563-024     | 84HP       | 1            | 172.5mm | 431.35mm | RoHS            |
| 34563-044     | 84HP       | 1            | 412.5mm | 431.35mm |                 |
| 34563-042     | 84HP       | 1            | 352.5mm | 431.35mm |                 |
| 34563-028     | 84HP       | 1            | 292.5mm | 431.35mm |                 |
| 34563-026     | 84HP       | 1            | 232.5mm | 431.35mm |                 |

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**