


Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

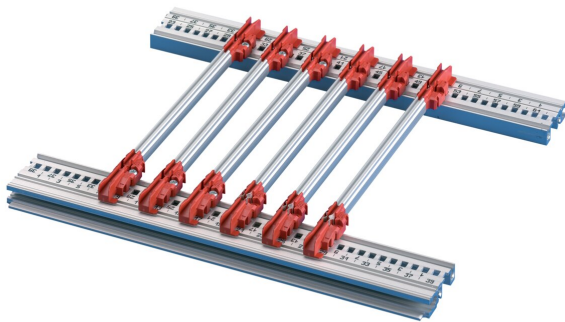

Guide rail mid-piece for individual multi-piece guide rails out of plastic or Aluminum extrusion. Suitable for Standard, Accessory, 4.4" PCB types and end pieces with coding.

FUNKTIONER

Middle profile for mounting guide rails for 2 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

Produktfamilie: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Product Type: Guide Rail
Type: Middle Section



SPECIFIKATIONER

Table 1/2

Katalognummer	Materiale	Farve	Pakke mængde	Board Depth	Groove Width	Farvekode
34560-891	Aluminium	Silver	1	160mm	2	
34560-893	Aluminium	Silver	1	280mm	2	
34564-891	PVC	Grey	1	160mm	2	RAL 7035
34564-893	PVC	Grey	1	280mm	2	RAL 7035
34564-900	PVC	Grey	1	1000mm	2	RAL 7035
34564-892	PVC	Grey	1	220mm	2	RAL 7035
34560-900	Aluminium	Silver	1	1000mm	2	
34560-892	Aluminium	Silver	1	220mm	2	

Table 2/2

Katalognummer	Finish	Works With
34560-891	Anodized	Subracks, Cases, Chassis
34560-893	Anodized	Subracks, Cases, Chassis
34564-891		Subracks, Cases, Chassis
34564-893		Subracks, Cases, Chassis
34564-900		Subracks, Cases, Chassis
34564-892		Subracks, Cases, Chassis
34560-900	Anodized	Subracks, Cases, Chassis
34560-892	Anodized	Subracks, Cases, Chassis

YDERLIGERE PRODUKTOPLYSNINGER

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE