


Panhead Screw, Torx, Self-Securing

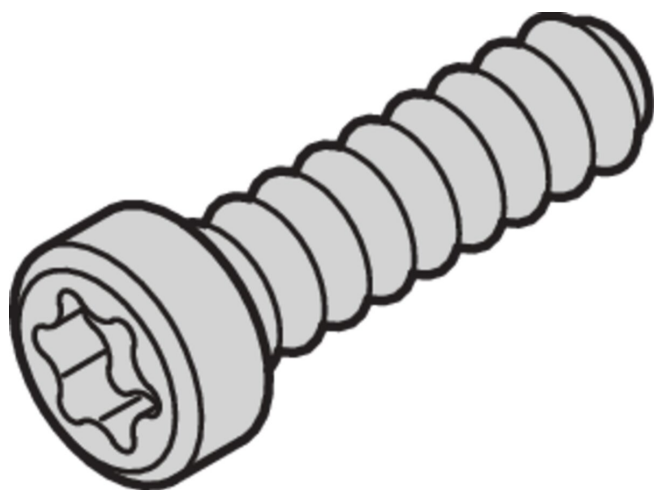

Good compromise between profile height and bearing area. Better load distribution than round heads. Compatible with automated assembly. Partially coated thread to prevent the screw from loosening on its own due to vibrations

Panhead Screw, Torx, St, zinc plated, M2.5 x 6 (Partially coated thread to prevent the screw from loosening on its own due to vibrations).

FUNKTIONER

Torx imprint bears greater torque

The star-shaped head prevents cam-out

Type: Panhead Screw
Product Type: Screw
Materiale: Stål



SPECIFIKATIONER

Katalognummer	Lengt h	Finish	Pakke mængde	Thread Size	Works With
24560-159	6mm	Forzinket Stål	100	M2.5	Backplanes, Test Adapters
21500-039	9.3m m	Forzinket Stål	100	M2.5	Front Panels, Horizontal Rails, Type H, Horizontal Rails, Type R

YDERLIGERE PRODUKTOPLYSNINGER

Torque max. 0.2 Nm.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE