


Panhead Screw, Torx

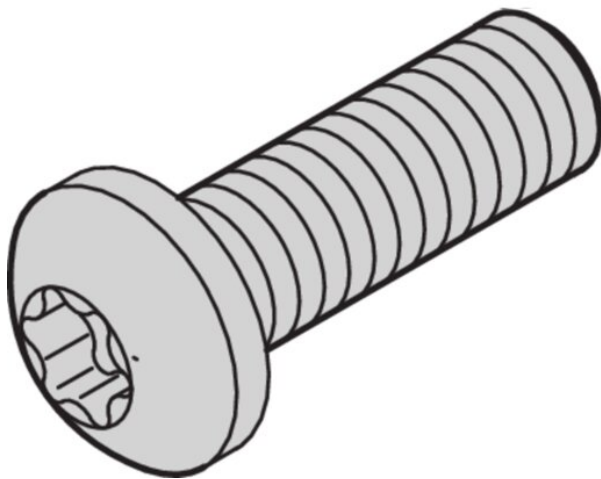

Good compromise between profile height and bearing area. Better load distribution than round heads. Compatible with automated assembly.

FUNKTIONER

Torx imprint bears greater torque

The star-shaped head prevents cam-out

Type: Panhead Screw
Product Type: Screw
Materiale: Stål



SPECIFIKATIONER

Katalognummer	Length	Finish	Pakke mængde	Thread Size	Produktfamilie	Works With	Torque
24560-148	10mm	Nickel Plated	100	M2.5		Backplanes, Test Adapters	0.3N· m
24560-147	7mm	Nickel Plated	100	M2.5	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO	Front Panels, Eurorack, Novastar, Varistar, Varistar CP	0.3N· m
24560-161	12mm	Nickel Plated	100	M2.5		Backplanes, Test Adapters	0.3N· m
24560-135	6mm	Forzinke t Stål	100	M4	EuropacPRO	Subracks	1.3N· m
24571-372	10mm	Forzinke t Stål	100	M4	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO	Front Panels, Eurorack, Novastar, Varistar, Varistar CP	2.4N· m
24571-371	14mm	Forzinke t Stål	100	M4	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO	Front Panels, Eurorack, Novastar, Varistar, Varistar CP	2.4N· m

Katalognummer	Length	Finish	Pakke mængde	Thread Size	Produktfamilie	Works With	Torque
24560-178	6mm	Nickel Plated	100	M2.5	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO	Front Panels, Eurorack, Novastar, Varistar, Varistar CP	
24560-162	14mm	Nickel Plated	100	M2.5		Backplanes, Test Adapters	
24560-163	16mm	Nickel Plated	100	M2.5		Backplanes, Test Adapters	

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE