

Plug-In Unit Kit With IEL Handle, Shielded, Black, 3 U



Plug-in unit, with IEL inserter/extractor black handle, 3 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

FUNKTIONER

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

Materiale:	Aluminium
Finish:	Anodized; Passivated
Product Type:	Front Panel
Type:	Front Panel with Handle (PIU)



SPECIFIKATIONER

Table 1/2

Katalognummer	Rack Width	Pakke mængde	Håndtagstype	Mounting	Gasket Type	Front Finish
20848-585	4HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-591	12HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-590	10HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-589	8HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-587	6HP	1	IEL	Screw-on Front	Textile EMC	Anodized


Table 2/2

Katalognummer	Rear Finish	Treated Edges	Complies With	EMC Shielding	Højde (H)	Rack Height	Bredde (W)
20848-585	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4m m	3U	20mm

Katalognummer	Rear Finish	Treated Edges	Complies With	EMC Shielding	Højde (H)	Rack Height	Bredde (W)
20848-591	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4m m	3U	60.6mm
20848-590	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4m m	3U	50.5mm
20848-589	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4m m	3U	40.3mm
20848-587	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4m m	3U	30.1mm

DIAGRAMS

3U

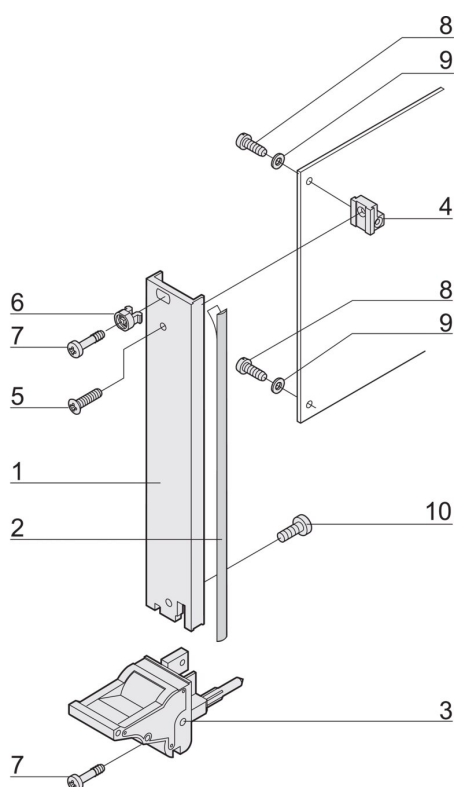

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE