


Rear Panel for RatiopacPRO/PropacPRO, Perforated, Retrofit Shielding

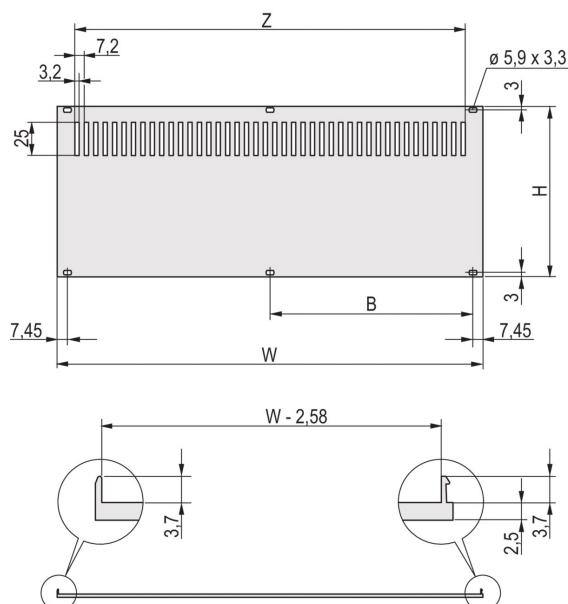

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

FUNKTIONER

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

Materiale:	Aluminium
Finish:	Anodized; Passivated
Works With:	Cases
Produktfamilie:	RatiopacPRO; RatiopacPRO AIR
Type:	Rear Panel
Product Type:	Side Panel



SPECIFIKATIONER

Katalognummer	Rack Height	Rack Width	Pakke mængde	Højde	Bredde
20848-744	5U	28HP	1	220mm	141.9mm
20848-656	4U	28HP	1	168.9mm	141.9mm
20848-659	4U	84HP	1	168.9mm	426.4mm
20848-658	4U	63HP	1	168.9mm	319.7mm
20848-679	2U	28HP	1	83.5mm	141.9mm
20848-643	6U	84HP	1	256mm	426.4mm
20848-681	2U	63HP	1	83.5mm	319.7mm
20848-682	2U	84HP	1	83.5mm	426.4mm
20848-642	6U	63HP	1	256mm	319.7mm

Katalognummer	Rack Height	Rack Width	Pakke mængde	Højde	Bredde
20848-640	6U	28HP	1	256mm	141.9mm
20848-634	3U	42HP	1	123.4mm	213mm
20848-657	4U	42HP	1	168.9mm	213mm
20848-636	3U	84HP	1	123.4mm	426.4mm
20848-745	5U	42HP	1	220mm	213mm
20848-641	6U	42HP	1	256mm	213mm
20848-746	5U	63HP	1	220mm	319.7mm
20848-635	3U	63HP	1	123.4mm	319.7mm
20848-747	5U	84HP	1	220mm	426.4mm
20848-680	2U	42HP	1	83.5mm	213mm
20848-633	3U	28HP	1	123.4mm	141.9mm

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE