


Varistar CP Top Cover Fan

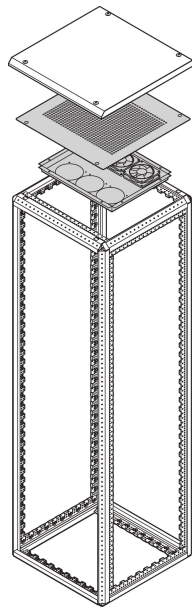

Varistar Fan Top Cover with 3 Fans, expandable to 6 fans.

FUNKTIONER

3 axial fans fitted (maximum: 6 fans)

C14 Socket

Please, review the listed product attributes to confirm every axial fan performance

Product Type: Fan
Materiale: Stål

SPECIFIKATIONER

Table 1/2

Katalognummer	Bredde	Dybde	Pakke mængde	Farve	Farvekode	Finish
21630-608	600mm	1200mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-602	600mm	1200mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-737	800mm	800mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-603	600mm	600mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-601	600mm	1100mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-604	600mm	800mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-605	600mm	900mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-736	800mm	600mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-600	600mm	1000mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-606	600mm	1000mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-607	600mm	1100mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-599	600mm	900mm	1	Black Grey	RAL 7021	Struktur Pulvermaling

Katalognummer	Bredde	Dybde	Pakke mængde	Farve	Farvekode	Finish
21630-612	800mm	1000mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-738	800mm	900mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-597	600mm	600mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-741	800mm	1200mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-740	800mm	1100mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-614	800mm	1200mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-613	800mm	1100mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-609	800mm	600mm	1	Black Grey	RAL 7021	Struktur Pulvermaling

Table 2/2

Katalognummer	Bredde	Dybde	Pakke mængde	Farve	Farvekode	Finish
21630-611	800mm	900mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-739	800mm	1000mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-610	800mm	800mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-598	600mm	800mm	1	Black Grey	RAL 7021	Struktur Pulvermaling

Table 1/2

Katalognummer	Beskyttelsesgrad	Works With
21630-608		Varistar CP
21630-602	IP20	
21630-737	IP20	
21630-603		Varistar CP
21630-601	IP20	
21630-604		Varistar CP
21630-605		Varistar CP
21630-736	IP20	
21630-600	IP20	
21630-606		Varistar CP
21630-607		Varistar CP
21630-599	IP20	
21630-612		Varistar CP
21630-738	IP20	
21630-597	IP20	
21630-741	IP20	
21630-740	IP20	
21630-614		Varistar CP

Katalognummer	Beskyttelsesgrad	Works With
21630-613		Varistar CP
21630-609		Varistar CP

Table 2/2

Katalognummer	Beskyttelsesgrad	Works With
21630-611		Varistar CP
21630-739	IP20	
21630-610		Varistar CP
21630-598	IP20	

YDERLIGERE PRODUKTOPLYSNINGER

Please purchase the grounding kit, power cable, Thermostat or Speed controller separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE