

# nVent CADDY Ladder Tray Clip

The nVent CADDY Ladder Tray Clip makes attaching ladder trays to strut profiles quick and easy—featuring a single-piece design, ready for use out-of-the box with no loose hardware.

Offering two simple installation methods, the Ladder Tray Clip can be either installed on top of the strut or slid in from either end of the channel, increasing flexibility and giving contractors more options on the job. Designed for both indoor and outdoor installations, the hot-dip galvanized finish and hardware ensure longevity on rooftop, solar and trapeze projects.



## MERKMALE

Single-piece design with hardware pre-installed to reduce components

Simple and time-saving; just drop and twist the Ladder Tray Clip directly into the strut profile

Works on ladder tray with up to ½ in flange thickness

Hot-dip galvanized clamp and hardware for demanding environments

Integrated clamping teeth for superior holding strength and load ratings



## SPEZIFIKATIONEN

Table 1/2

| Katalognummer | Material | Oberfläche    | Flanschstärke (FT) | A     | B       | Drehmoment (TQ) |
|---------------|----------|---------------|--------------------|-------|---------|-----------------|
| LTC           | Stahl    | Feuerverzinkt | 13 mm Max          | 49 mm | 38.1 mm | 41 N·m          |

Table 2/2

| Katalognummer | Statische Grenzlast 1 (F1) | Statische Grenzlast 2 (F2) | Statische Grenzlast 3 (F3) |
|---------------|----------------------------|----------------------------|----------------------------|
| LTC           | 2225N                      | 3100N                      | 10675N                     |

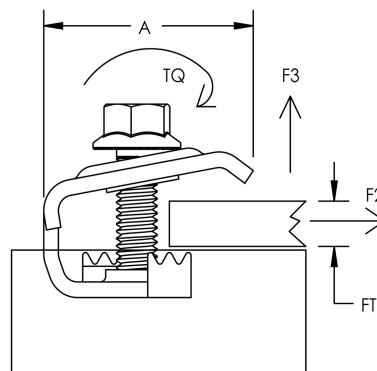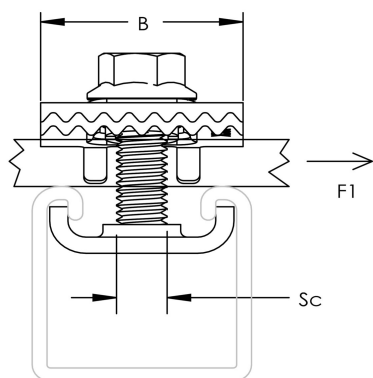

## WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter [www.nVent.com](http://www.nVent.com) sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

### Nordamerika

+1.800.753.9221  
Option 1 – Kundendienst  
Option 2 – Technischer  
Support

### Europa

Niederlande:  
+31 800-0200135  
Frankreich:  
+33 800 901 793

### Europa

Deutschland:  
800 1890272  
Sonstige Länder:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Unser starkes markenportfolio:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

