

Front Panel, Front Shielded, Side Hinged

Front panel with textile EMC gasket, side hinged assembly.

FEATURES

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

Depth (D):	2.5mm
Rack Width:	84HP
Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle
EMC Shielding:	No (Retrofittable)




SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Package Quantity	Mounting	Gasket Type	Front Finish	Rear Finish
20848-611	3U	1	Hinged, Side	Textile EMC	Anodized	Conductive
20848-617	6U	1	Hinged, Side	Textile EMC	Anodized	Conductive

Table 2/2

Catalog Number	Treated Edges	Height (H)	Width (W)
20848-611	No	128.4mm	426.4mm
20848-617	No	261.8mm	426.4mm

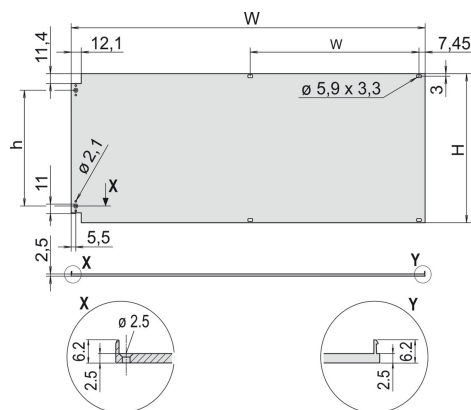

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE