


nVent CADDY Adjustable Depth Multi-Gang Masonry Open Back Box

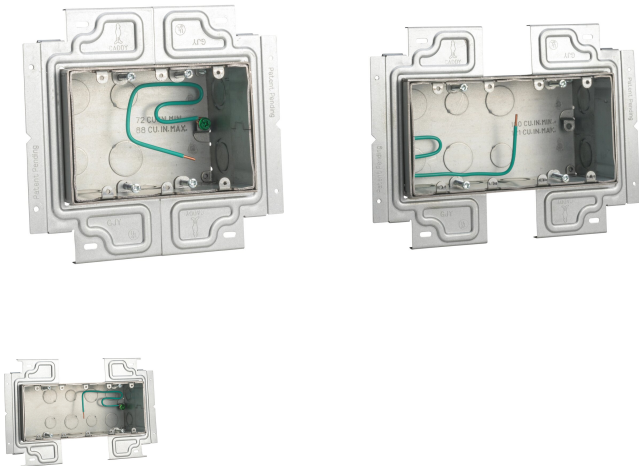

The nVent CADDY Adjustable Depth Multi-Gang Open Back Box incorporates several innovative features to create a cost-effective solution for installing up to six devices in a single box. The box is designed with a masonry style front, eliminating the need for a mud ring. By incorporating an inner ring, the depth is fully adjustable from ½ to 1 ½ inches. Installers have the ability to remove the back of the box for easy access to device wiring. In addition, the box can be mounted direct-to-stud or assembled between-stud with the nVent CADDY Heavy Duty Between-Stud Bracket.

FEATURES

Adjustable mud ring design accommodates various thicknesses of drywall and can be adjusted after installation

Snap-on installation to nVent CADDY Heavy Duty Telescoping Bracket allows for easy positioning along bracket

Features ½, ¾, and 1 in multiple knockouts on the top and bottom; and ½ and ¾ in multiple knockouts on the side

Choose between four different size options: three, four, five and six gang

Can be mounted directly to metal studs

Integral far-side support for on-stud mounting up to 6 in stud depths

Innovative box lock tab secures box to bracket during assembly

Open-back methodology provides versatility and installation efficiency

Finish: Pregalvanized

Material: Steel






SPECIFICATIONS

Catalog Number	Length (L)	Width (W)	Height 1 (H1)	Height 2 (H2)	Height 3 (H3)	Drywall Thickness
TB5GM	294.11mm	187.01mm	92.08mm	106.05mm	130.18mm	12.7 - 38.1 mm
TB4GM	248.06mm	187.01mm	92.08mm	106.05mm	130.18mm	12.7 - 38.1 mm
TB3GM	202.02mm	187.01mm	92.08mm	106.05mm	130.18mm	12.7 - 38.1 mm

Catalog Number	Length (L)	Width (W)	Height 1 (H1)	Height 2 (H2)	Height 3 (H3)	Drywall Thickness
TB6GM	340.13mm	187.01mm	92.08mm	106.05mm	130.18mm	12.7 - 38.1 mm

DIAGRAMS

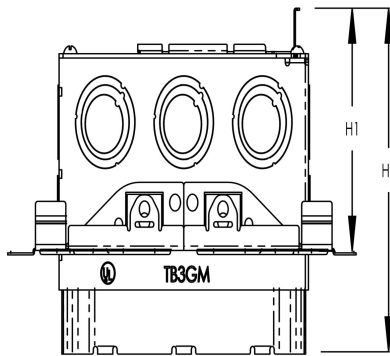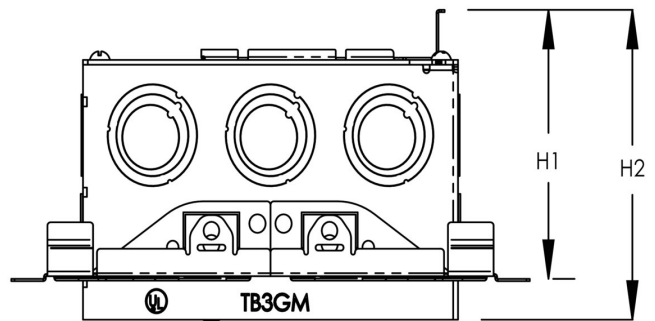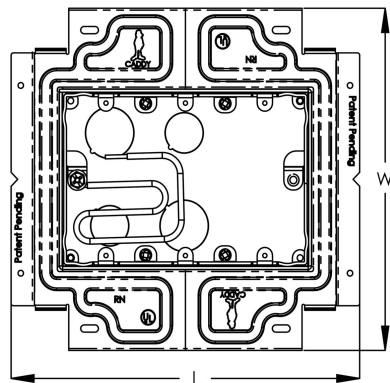

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

