


nVent CADDY In-Deck Plastic Foot

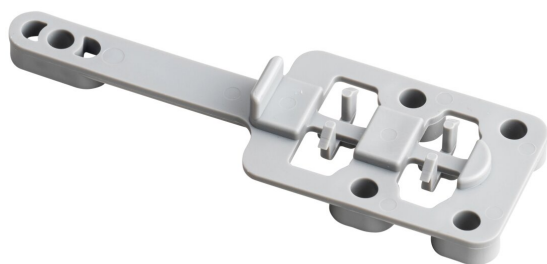

The nVent CADDY In-Deck Plastic Foot is a convenient method to minimize electrical installation exposure for concrete deck applications. The In-Deck Plastic Foot series is designed to provide a tool-free method of attachment to the nVent CADDY In-Deck Stub Up and Adjustable Box Supports, giving confidence the installation will meet the “no exposed metal” requirements.

FEATURES

Easy, tool-free attachment



1/4 in spacing allows for concrete flow

Grey color minimizes visibility

SPECIFICATIONS

Catalog Number	Length (L)	Width (W)	Height (H)
FBSPF	98.3mm	31.8 mm	13.7 mm

DIAGRAMS

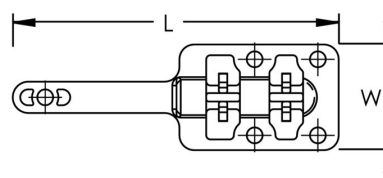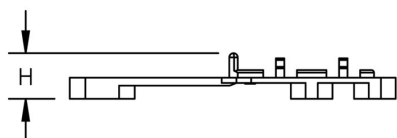

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

