

SOSR Stand Off Two Hole Strap for CPVC Pipe



FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Positions pipe 1-1/2" (38 mm) off the mounting surface eliminating the need for wooden spacer blocks

Can be mounted in both vertical and horizontal positions on concrete, steel and wood

Meets the UL® 203 stringent upward thrust requirement

UL® Listed as both a hanger and pipe restraint

Complies with static load requirements of NFPA® 13

Includes mounting screws



Can be used with 3TW backing nut on composite wood joist installations

Finish: Pregalvanized
Material: Steel



SPECIFICATIONS

Catalog Number	NB/DN	Hole Size (HS)	A	B	C	Thickness (T)	Hanger Spacing
SOSR125	32	5.1 mm	84 mm	92 mm	25.4 mm	1.61 mm	1.95 m Max
SOSR075	20	5.1 mm	68 mm	92 mm	25.4 mm	1.3 mm	1.65 m Max
SOSR150	40	5.1 mm	98 mm	114 mm	25.4 mm	1.61 mm	2.1 m Max
SOSR100	25	5.1 mm	75 mm	94 mm	25.4 mm	1.3 mm	1.8 m Max
SOSR200	50	5.1 mm	102 mm	133 mm	25.4 mm	1.61 mm	2.4 m Max

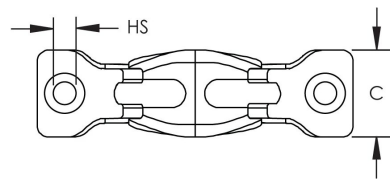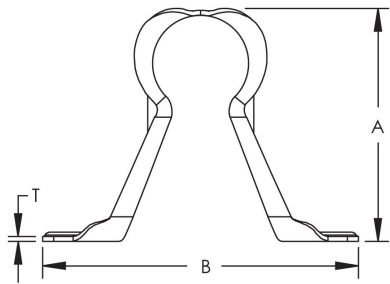

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

