


CFF Tapered Screw-In Plug for A12, A22 and A32K Couplers

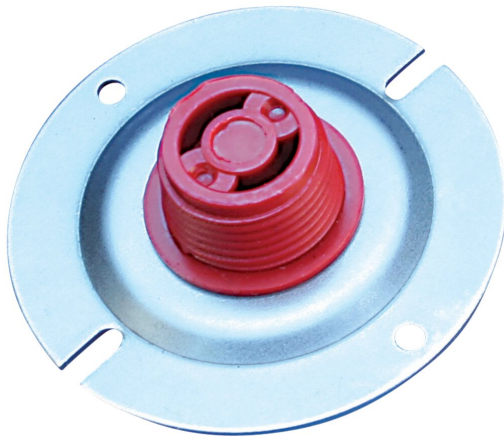

FEATURES

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour


Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

Material: High Density Polyethylene (HDPE);Steel

SPECIFICATIONS

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL28CFF	28 mm	#9	30M	75 mm	18 mm	Black	25
EL30CFF	30 mm			75 mm	18 mm	White	25
EL50CFF	50 mm			95 mm	18 mm	Black	15
EL22CFF	22 mm	#7		75 mm	18 mm	Blue	25
EL32CFF	32 mm	#10		95 mm	18 mm	Yellow	15
EL36CFF	36 mm	#11	35M	95 mm	18 mm	Blue	15
EL25CFF	25 mm	#8	25M	75 mm	18 mm	Red	25
EL40CFF	40 mm			95 mm	18 mm	Green	15

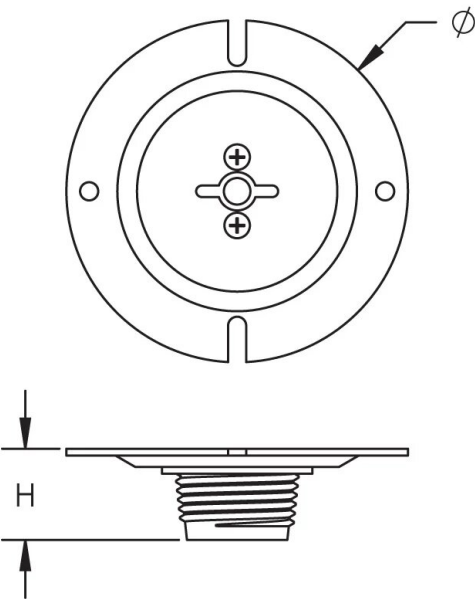

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE