

CFFP Tapered Plastic Screw-In Plug for A12, A22 and A32K Couplers



FEATURES

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size


Material: Polyethylene

SPECIFICATIONS

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL28CFFP	28 mm	#9	30M	59 mm	23 mm	Black	100
EL12CFFP	12 mm	#4	10M	59 mm	23 mm	Red	100
EL25CFFP	25 mm	#8	25M	59 mm	23 mm	Red	100
EL20CFFP	20 mm	#6	20M	59 mm	23 mm	Yellow	100
EL14CFFP	14 mm			59 mm	23 mm	Green	100
EL16CFFP	16 mm	#5	15M	59 mm	23 mm	Black	100

ADDITIONAL PRODUCT DETAILS

EL12CFFP and EL16CFFP can also be used on the A2 coupler families.

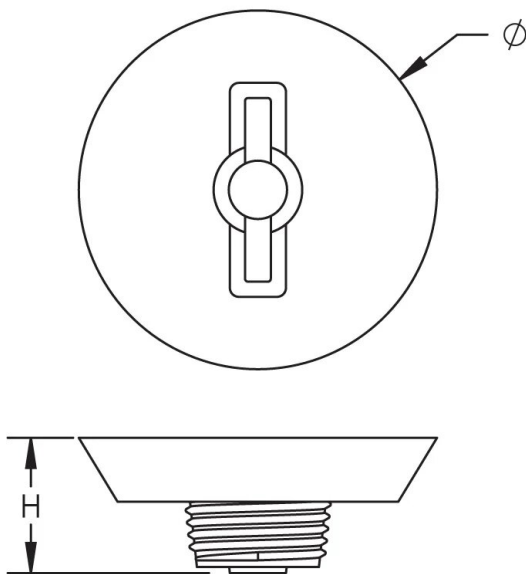

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE