

CPP Tapered Plastic Screw-In Plug for A12, A22 and A32K



FEATURES

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size


Material: High Density Polyethylene (HDPE)

SPECIFICATIONS

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL16CPPB100	16 mm	#5	15M	22 mm	13 mm	Black	100
EL14CPPB100	14 mm			22 mm	13 mm	Green	100
EL10CPPB100	10 mm	#3		17 mm	13 mm	Yellow	100
EL18CPPB100	18 mm			27 mm	13 mm	White	100
EL12CPPB100	12 mm	#4	10M	17 mm	13 mm	Red	100
EL20CPPB100	20 mm	#6	20M	27 mm	13 mm	Yellow	100
EL25CPPB100	25 mm	#8	25M	33 mm	16 mm	Red	100
EL36CPPB50	36 mm	#11	35M	46 mm	16 mm	Blue	50
EL32CPPB100	32 mm	#10		42 mm	16 mm	Yellow	100

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL30CPPB100	30 mm			37 mm	16 mm	White	100
EL40CPPB50	40 mm			52 mm	16 mm	Green	50
EL28CPPB100	28 mm	#9	30M	37 mm	16 mm	Black	100
EL22CPPB100	22 mm	#7		33 mm	16 mm	Blue	100
EL50CPPB40	50 mm			64 mm	16 mm	Black	40

DIAGRAMS

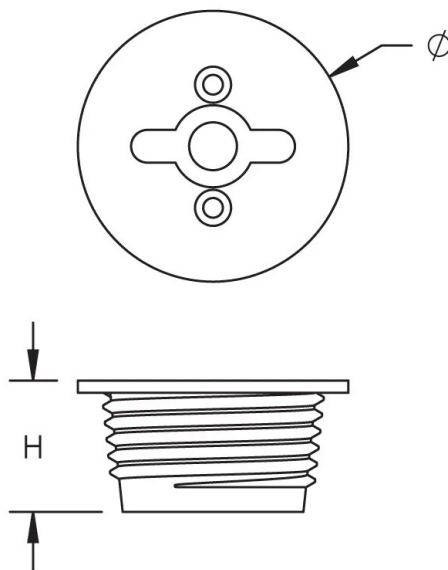

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE