

# EuropacPRO Advanced EMC Side Panel Cover


Aluminium Side panel 3mm to increase the EMC shielding effect of the subrack by covering the not needed cut-outs.

## FEATURES

Side panel covers for increased lateral RF shielding

Assembled on the outside of the standard side panel

Assembly material included

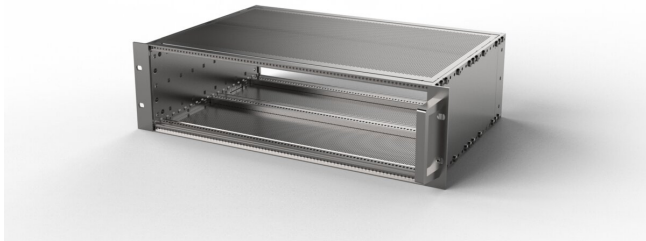

|                        |            |
|------------------------|------------|
| <b>Material:</b>       | Aluminum   |
| <b>Product Family:</b> | EuropacPRO |
| <b>Finish:</b>         | Passivated |
| <b>Product Type:</b>   | Side Panel |
| <b>Works With:</b>     | Subracks   |
| <b>Type:</b>           | Type H     |
| <b>EMC Shielding:</b>  | Yes        |



## SPECIFICATIONS

Table 1/2

| Catalog Number | Rack Height | Depth    | Package Quantity | Length   | Package Unit |
|----------------|-------------|----------|------------------|----------|--------------|
| 24563-256      | 3U          | 235mm    | 2                | 235mm    | Pair         |
| 24563-268      | 4U          | 355mm    | 2                | 355mm    | Pair         |
| 24563-257      | 3U          | 275mm    | 2                | 275mm    | Pair         |
| 24563-269      | 4U          | 415mm    | 2                | 415mm    | Pair         |
| 24563-267      | 4U          | 295mm    | 2                | 295mm    | Pair         |
| 24563-266      | 4U          | 235mm    | 2                | 235mm    | Pair         |
| 24563-270      | 4U          | 495mm    | 2                | 495mm    | Pair         |
| 24563-265      | 4U          | 175mm    | 2                | 175mm    | Pair         |
| 24563-275      | 6U          | 175mm    | 2                | 175mm    | Pair         |
| 24563-258      | 3U          | 277.75mm | 2                | 277.75mm | Pair         |
| 24563-276      | 6U          | 235mm    | 2                | 235mm    | Pair         |
| 24563-262      | 3U          | 495mm    | 2                | 495mm    | Pair         |
| 24563-277      | 6U          | 275mm    | 2                | 275mm    | Pair         |

| Catalog Number | Rack Height | Depth    | Package Quantity | Length   | Package Unit |
|----------------|-------------|----------|------------------|----------|--------------|
| 24563-261      | 3U          | 415mm    | 2                | 415mm    | Pair         |
| 24563-278      | 6U          | 277.75mm | 2                | 277.75mm | Pair         |
| 24563-279      | 6U          | 295mm    | 2                | 295mm    | Pair         |
| 24563-260      | 3U          | 355mm    | 2                | 355mm    | Pair         |
| 24563-280      | 6U          | 355mm    | 2                | 355mm    | Pair         |
| 24563-281      | 6U          | 415mm    | 2                | 415mm    | Pair         |
| 24563-259      | 3U          | 295mm    | 2                | 295mm    | Pair         |

Table 2/2

| Catalog Number | Rack Height | Depth | Package Quantity | Length | Package Unit |
|----------------|-------------|-------|------------------|--------|--------------|
| 24563-282      | 6U          | 495mm | 2                | 495mm  | Pair         |
| 24563-255      | 3U          | 175mm | 2                | 175mm  | Pair         |

## ADDITIONAL PRODUCT DETAILS

Side panel and 19" bracket are tox-cold welded together. toxen = Clinching technique, without add aids. This takes place with special tools and high pressure.

9 U version available on request.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**