


Mounting Plates Wall Mounted Enclosures, AMP

The steel mounting plate contributes to speeding up the assembly of the enclosure, since it can be machined easily and equipped with components before being mounted.

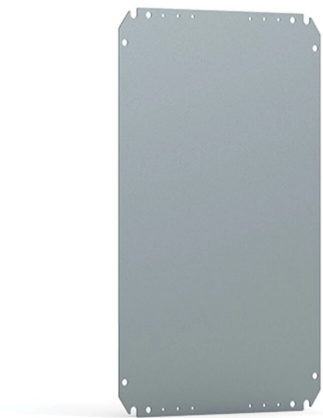

FEATURES

Description: Steel mounting plate for wall mounted enclosures. All sizes from 800 mm and above are strengthened by folded edges. By using the AMG accessory, the mounting plate position can be adjusted to any depth. This accessory is not suitable for the AFS range of enclosures, please refer to the replacement and spare parts catalogue.

Material: Galvanized steel.

Pack quantity: 1 piece.

Thickness: 2mm
Finish: Galvanized
Material: Mild Steel

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Height	Width	Depth	Panel Size	Enclosure Material
AMP06050	AMP06050	600mm	500mm	2mm	570 x 450mm	Mild Steel
AMP02525	AMP02525	250mm	249mm	2mm	220 x 200mm	Mild Steel
AMP05040	AMP05040	500mm	350mm	2mm	470 x 350mm	Mild Steel
AMP05030	AMP05030	500mm	299mm	2mm	470 x 250mm	Mild Steel
AMP02520	AMP02520	250mm	199mm	2mm	220 x 150mm	Mild Steel
AMP04030	AMP04030	400mm	299mm	2mm	370 x 250mm	Mild Steel
AMP06060	AMP06060	600mm	599mm	2mm	570 x 550mm	Mild Steel
AMP03025	AMP03025	300mm	249mm	2mm	270 x 200mm	Mild Steel
AMP04040	AMP04040	400mm	400mm	2mm	370 x 350mm	Mild Steel
AMP03030	AMP03030	300mm	299mm	2mm	270 x 250mm	Mild Steel

Catalog Number	Article Number	Height	Width	Depth	Panel Size	Enclosure Material
AMP03525	AMP03525	350mm	249mm	2mm	320 x 200mm	Mild Steel
AMP07050	AMP07050	700mm	500mm	2mm	670 x 450mm	Mild Steel
AMP03040	AMP03040	300mm	400mm	2mm	270 x 350mm	Mild Steel
AMP04060	AMP04060	400mm	599mm	2mm	370 x 550mm	Mild Steel
AMP03060	AMP03060	300mm	599mm	2mm	270 x 550mm	Mild Steel
AMP06080	AMP06080	600mm	799mm	2mm	570 x 750mm	Mild Steel
AMP06040	AMP06040	600mm	400mm	2mm	570 x 350mm	Mild Steel
AMP03080	AMP03080	300mm	799mm	2mm	270 x 750mm	Mild Steel
AMP05050	AMP05050	500mm	500mm	2mm	470 x 450mm	Mild Steel
AMP04050	AMP04050	400mm	500mm	2mm	370 x 450mm	Mild Steel

Table 2/2

Catalog Number	Article Number	Height	Width	Depth	Panel Size	Enclosure Material
AMP02020	AMP02020	200mm	199mm	2mm	170 x 150mm	Mild Steel
AMP10060	AMP10060	1000mm	599mm	12mm	970 x 550mm	Mild Steel
AMP12100	AMP12100	1200mm	999mm	12mm	1170 x 950mm	Mild Steel
AMP08060	AMP08060	800mm	599mm	12mm	770 x 550mm	Mild Steel
AMP12080	AMP12080	1200mm	799mm	12mm	1170 x 750mm	Mild Steel
AMP08120	AMP08120	800mm	1199mm	12mm	770 x 1150mm	Mild Steel
AMP12060	AMP12060	1200mm	599mm	12mm	1170 x 550mm	Mild Steel
AMP03120	AMP03120	300mm	1199mm	12mm	270 x 1150mm	Mild Steel
AMP10080	AMP10080	1000mm	799mm	12mm	970 x 750mm	Mild Steel
AMP03100	AMP03100	300mm	999mm	12mm	270 x 950mm	Mild Steel
AMP08080	AMP08080	800mm	799mm	12mm	770 x 750mm	Mild Steel
AMP12120	AMP12120	1200mm	1199mm	12mm	1170 x 1150mm	Mild Steel
AMP08040	AMP08040	800mm	400mm	12mm	770 x 350mm	Mild Steel
AMP10120	AMP10120	1000mm	1199mm	12mm	970 x 950mm	Mild Steel
AMP14100	AMP14100	1400mm	999mm	12mm	1370 x 950mm	Mild Steel
AMP10100	AMP10100	1000mm	999mm	12mm	970 x 950mm	Mild Steel

ADDITIONAL PRODUCT DETAILS

Not suitable for AFS.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE