


Front Panel, Retrofit Shielding, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

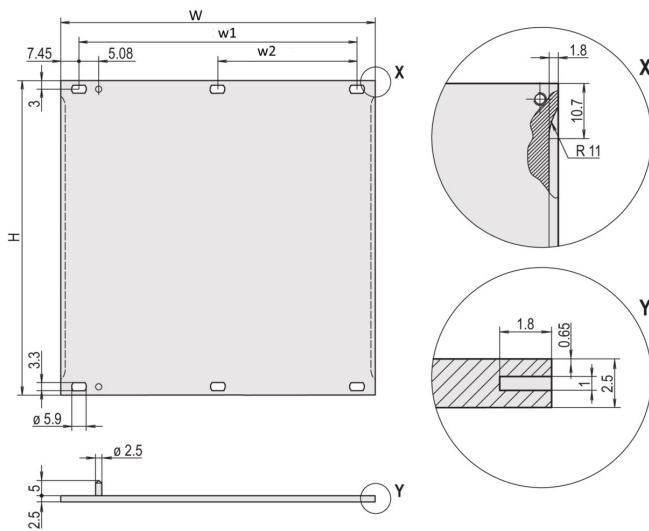

CATALOG NUMBER

30846-676

Flat front panel. Shieldable with stainless steel EMC gasket.

FEATURES

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive



PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 84HP

Package Quantity: 1

Accessory Type: Front panel

Mounting: Screw-on Front

Gasket Type: Stainless Steel EMC

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Depth (D): 2.5mm

EMC Shielding: No (Retrofittable)

Finish: Anodized; Passivated

Height (H): 128.4mm

Material: Aluminum

